

TIE10 MounTie

Mount-Hole Cable Ties Black


UV-RESISTANT

HALOGEN-FREE

UL 94 V-2

ROHS COMPLIANT

CE

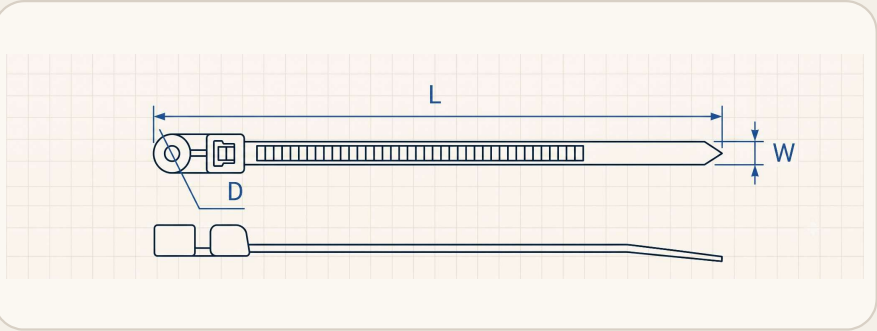

Technical specification

Material	Polyamide 6.6 + 1% carbon black
Hole diameter	5 mm
Colour	Black
Flammability	UL 94 V-2
Halogen-free	Yes
UV exposure	Resistant <i>suitable for outdoor use</i>
Moisture absorption	2.7% at 23 °C and 50% R.H.
Working temperature	-40 °C to +85 °C
Installation temperature	-10 °C to +60 °C
Resistant to	Aromatic solvents, oils, greases and derivatives
Limited resistance	Acids
Not resistant to	Phenols and chlorinated solvents

Range & item codes

ITEM CODE	SIZE	W (MM)	L (MM)	MAX Ø (MM)	N	KGF	PCS/PACK	PCS/CARTON
TTF3.6X150B	3.6X150 mm	3.6	150	Ø35	178	18	100	8,000
TTF4.6X200B	4.6X200 mm	4.6	200	Ø50	216	22	100	6,000

N / kgf = minimum loop tensile strength.