

Delock Antenna Cable RP-SMA Plug > RP-SMA Jack CFD400 LLC400 2 m low loss

Opis

This high-quality coaxial cable ensures a reliable connection of components of the radio frequency technology. It is characterized by a very low attenuation.



Numer artykułu 13014

EAN: 4043619130146

Kraj pochodzenia:
Taiwan, Republic of
China

Opakowanie: White Box

Szczegóły techniczne

- Connectors: RP-SMA plug > RP-SMA jack
- Cable type: CFD400, LLC400
- Impedance: 50 Ohm
- Cable attenuation:
 - 2.4 GHz: ca. 0.22 dB per meter
 - 5.7 GHz: ca. 0.35 dB per meter
- Diameter: ca. 10.5 mm
- Smallest bending radius: 51.5 mm
- Colour: black
- Cable length: ca. 2 m


Wymagania systemowe

- Device with free RP-SMA connector

Zawartość opakowania

- Antenna cable

Zdjęcia

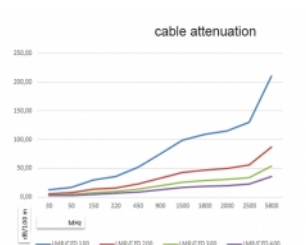

Interfejs

Złącze 1:	1 x męski RP-SMA
Złącze 2:	1 x RP-SMA żeński

Właściwości techniczne

Impedancja:	50 Ω
-------------	------

Właściwości fizyczne

Typ przewodu:	CFD400, LLC400
Tłumienie przewodu:	0,22 dB @ 2,4 GHz na metr 0,35 dB @ 5,7 GHz na metr
Kolor przewodu:	czarny
Długość kabla:	2 m
Średnica kabla:	10,5 mm

Manufacturer information

Ulica	Beeskowdamm 13/15
Kod pocztowy	14167
Miasto	Berlin
Kraj	Deutschland
Email	info@delock.de
Strona internetowa	www.delock.de

