
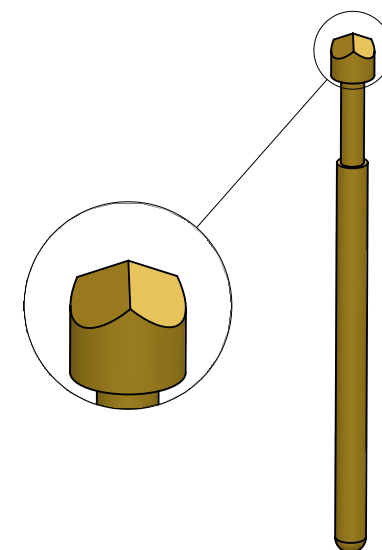


mm [inch]

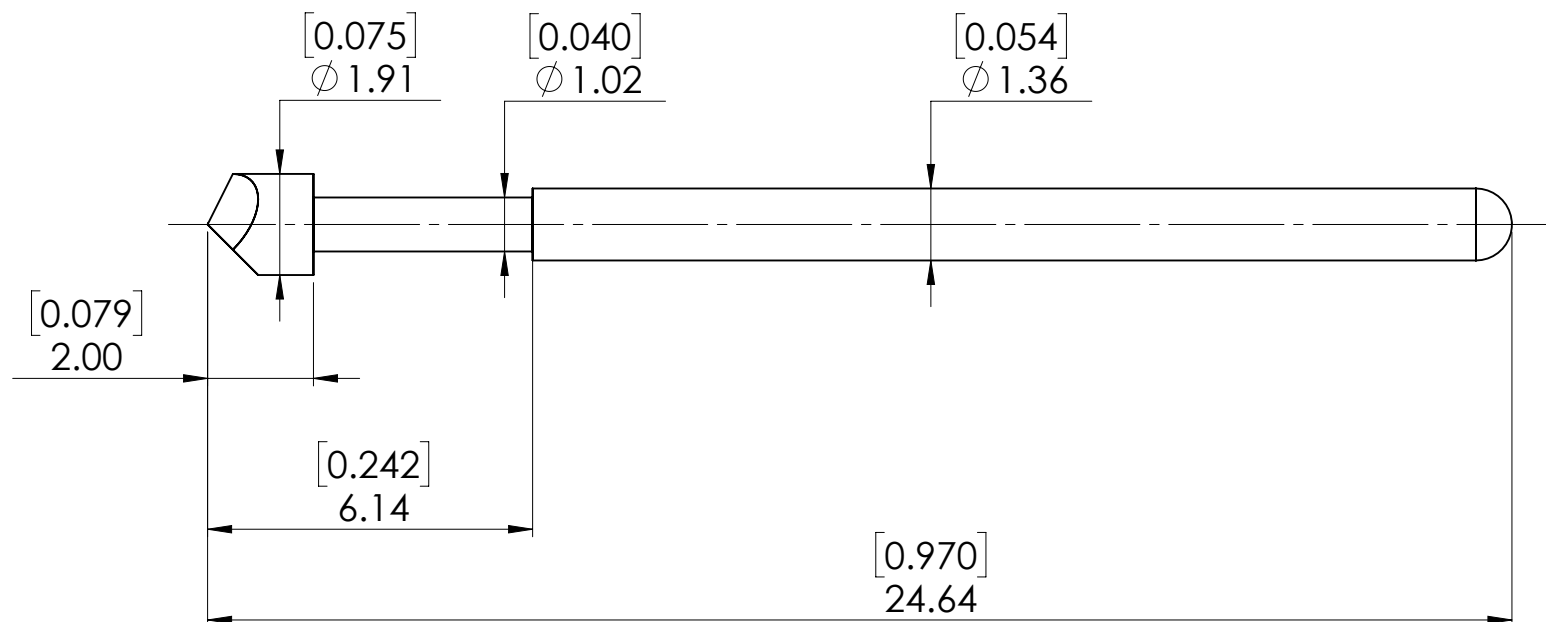

ST1011 ER06 SX

Minimum centers: 2.54 [.100]
 Full travel: 4.20 [.165]
 Working travel: 2.80 [.110]
 Current rating: 3 A
 Probe resistance: < 100mΩ
 Operating temperature: -50°C up to +150°C
 Plunger material: BeCu / gold plated
 Barrel material: PhBr / gold plated
 Spring material: Stainless steel

Spring force at working stroke: 1.0N[3.6 oz]

© COPYRIGHT 2021 EQUIP-TEST KFT. ALL RIGHTS RESERVED This drawing, model, intellectual product belongs to Equip-Test Kft. Forwarding it to 3rd. party, copying it or using for any other purpose without the written approval of Equip-Test Kft., could entail to legal and criminal procedure!		Name	Date	Catalog Item: ST1011 ER06 SX	
	Designed	M.K.	24.02.2022.	Drawing No.:	
	Drawed				
	Checked				
Note				A4 SHEET 1 OF 1	