

MILAN S.r.l. a socio unico

Head Office – Export department:  
Viale Europa, 74  
20090 Cusago (MI) Italy  
T. +39 02 9039.4556-4158  
F. +39 02 9039.4551  
www.taskercables.com


Ufficio Commerciale e Centro Distribuzione  
Viale Europa 72 Strada F12  
20090 Cusago (MI) Italy  
T. +39 02 9039.0037-0059  
F. +39 02 9039.0049  
www.tasker.it

✓  
RoHS<sub>2</sub>  
2002/95/EC  
2011/65/UE



**Firestop®** Technical Datasheet

**tasker® C6035 CPR – 6x0,35 mm<sup>2</sup>**  
**Braided Shielded Cable**

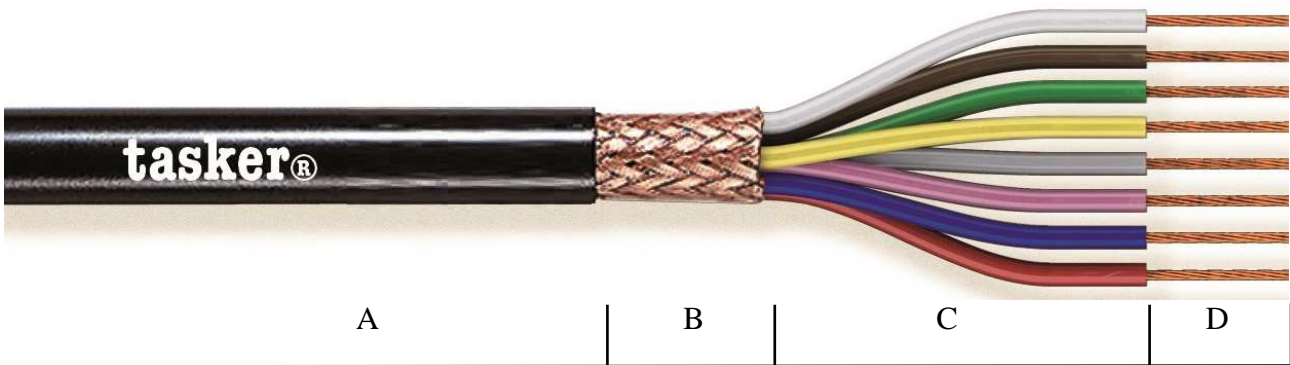

**NOTE**  
**CATEGORY**  
**APPLICATIONS**

The picture does not represent the real number of conductors  
Braided Conductor Shielded Cable (See Data Network Catalogue)  
Data transmission and Electronics

- A:** Black **Flame Retardant PVC** sheath.  
Outer cable diam. Ø 7,20 (±0,20) mm.
- B:** Braided Shielding O.F.C. Red Copper covering 85%.
- C:** Cores Insulation with **Flame Retardant PVC**.  
Core color code with DIN 47100 Standards.  
Diam. Ø 1,60 (±0,20) mm.
- D:** Stranded O.F.C. Red Copper formation 11x0,20 mm.  
Nom. Cross section 6x0,35 mm<sup>2</sup>.

**MARKING**

**tasker®** C6035 CPR 6x0,35 mm<sup>2</sup> O.F.C. - IMQ 0051-CPR-0966 – 2017 – Eca –  
BRAIDED SHIELDED CABLE - Firestop® - Made Italy

**Cable Properties**

<b>Conductor Resistance</b>	58,00 Ω/Km
<b>Capacity Core/Core</b>	120 pF/mt
<b>Capacity Core/Shield</b>	210 pF/mt
<b>Max Rated Voltage</b>	49 V
<b>Operative Temperature</b>	-20/+70°C

<b>USE</b>	<b>X</b>	Indoor	Interno Edificio
<b>Impiego</b>	<b>X</b>	Outdoor Limited	Esterno Limitato
		Outdoor	Esterno
		Outdoor Direct Burial	Esterno Interrato

<b>INSTALLATION</b>	<b>X</b>	Fixed	Fissa
<b>Posa</b>	<b>X</b>	Restricted Mobile	Mobile Limitata
		Mobile	Mobile
		Mobile in Drag Chain	Mobile in Catena

<b>INFORMATION</b>	<b>X</b>	RoHS2 Compliant
<b>Informazioni</b>	<b>X</b>	Ver. A / 26.05.17