


[XM-L2 U3 LED]

**Maximum Output 1100Lm,
50000h Lifespan,
Orange Peel Reflector.**



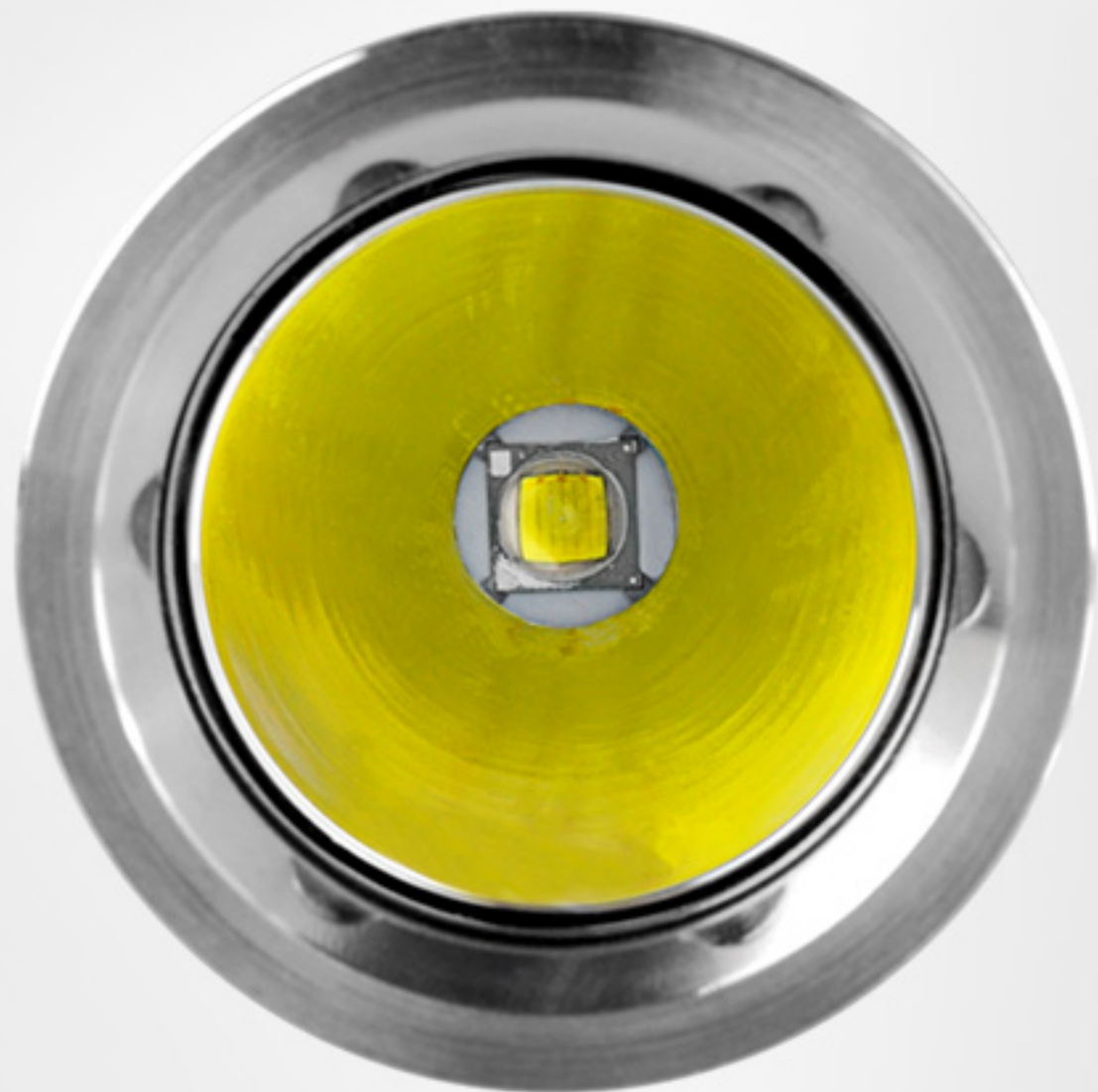

[Glass Lens]

Ultra-clear Tempered Glass Lens with Anti-reflective Coating.

Common Glass: 89-92% Transmittance.

**98.5
%**

Transmittance



Low mode 30Lm
Runtime 75h




Mid mode/Signal 250Lm
Runtime 8.5h(Only Mid mode)



High mode 600Lm
Runtime 3.5h



Turbo mode 1100Lm
Runtime 3.3h

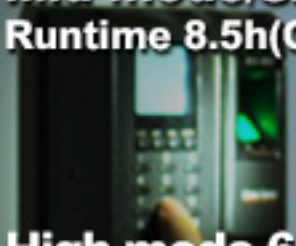

[Lighting Modes]

Wide Beam with Superior Distance.

1. 4 Lighting modes: Low Mid High Turbo.
2. 1 Hidden modes: Signal.
3. Max output 1100Lm.
4. Max Intensity 13225cd.
5. Beam Throw 230m.

XTAR

[Switch]

Rear forward tactical switch.

Environmental friendly waterproof silicone material plus wear-resisting feature.



[Use Method]

Ergonomic design, More comfortable to hold and operate.

1. One switch with double operation method: Click heavily to turn on/off and change modes directly Flip for momentary on, click heavily for locked on.
2. Signal mode: When the B20 Pilot II is closed, Quick double-click to get Hidden signal mode.





[**Stainless Steel Clip**]

Sturdy and durable.

Anodized aircraft 6N01 aluminum alloy
Type III Hard-anodized anti-abrasive finish.



[Low Heat Design]

**Excellent heat dissipation design.
Extend flashlight lifespan.**



[Appearance design]

Headstand, Tailstand,
Anti-roll.



[Spring, Circuit]

**Dual anti-oxidant Gold-plated spring
Avoid the poor contact.**

+ Transverse conductive, reversive polarity protection, more secure.
High efficiency drive circuit, runtime curve is more stable.



[Battery Type]

**Compatible with
18650 Li-ion battery and 18700 Li-ion battery**





[Waterproof Level]
Waterproof IPX8
(Underwater 2m)




[Application Range]

Versatile.

Max beam throw 230m, Orange Peel Reflector, wide beam, beautiful floodlight, suitable for various usage.



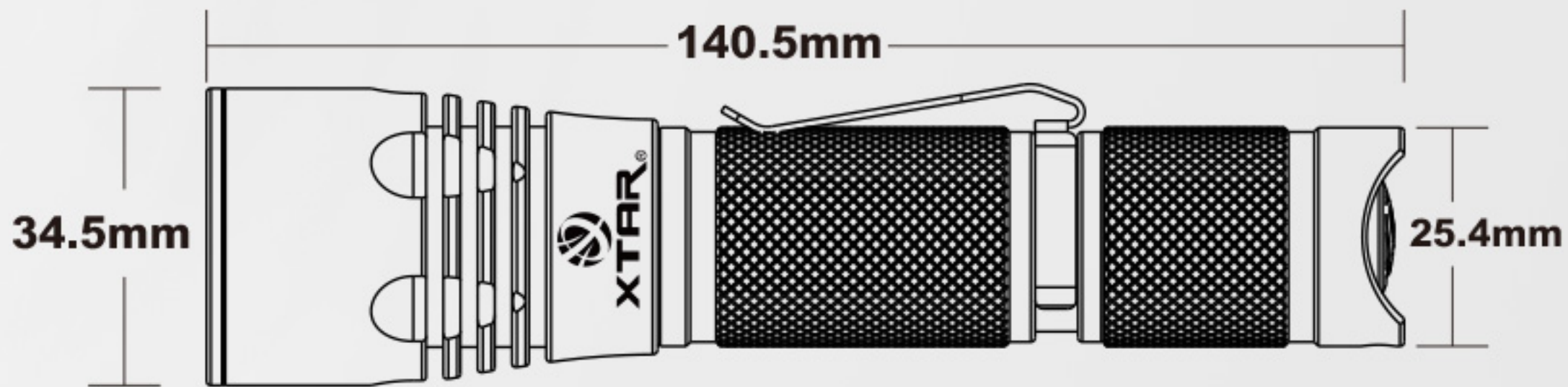







[Size and Net Weight]

Net Weight: 120.0g (Battery excluded).

[B20 Specification]

ANSI	Illumination levels				
	Turbo	High	Middle	Low	Signal
 Luminance	1100Lm	600Lm	250Lm	30Lm	250Lm
 Runtime	3.3h	3.5h	8.5h	75h	/
 Beam Throw	230m				
 Max Intensity	13225cd				
 Impact Resistant	1.5m				
 Waterproof	IPX8				
LED	CREE XM-L2 U3				
Material	Anodized aircraft 6N01 aluminium alloy, Type III hard-anodized anti-abrasive finish				
Working Voltage	2.75V—4.2V				
Batteries	1 × 18650				
Switch	Rear Forward Tactical Switch				
Size	Φ34.5mm(Head dia) × Φ25.4mm(Body dia) × Φ25.4mm(Tail dia) × 140.5mm(Length)				
Net Weight	120g (Excluded battery)				
Additional Functions	Memory function, Reverse polarity protection				
Package Contents	Flashlight, Stainless Steel clip, Lanyard, Holster, Spare O-ring, Manual, Warranty Card				
Optional Accessories	Battery or Charger				