




DIN 85 A

~ISO 1580

4.8

Norme abrogée

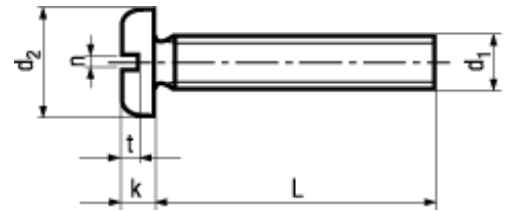

BN 344

Vis à tête aplatie Pan-Head

à fente

Acier 4.8

zingué-bleu

- ~UNI 6108
- ~ČSN 021137



Toutes les longueurs avec filetage ~ sous tête

M2,5: selon ISO 1580, M2,6: n'est pas dans DIN 85 et ISO 1580

Article#	d ₁	d ₂	k max.	n	t min.	L
1432133	M2,5	5	1,5	0,6	0,6	3
1130757						4
1130765						5
1130773						6
1130781						8
1130803						10
1130811						12
1130838						(14)
1130846						16
1130854						(18)
1130862						20
1130870						(22)
1130889						25
1130897						30
1130900	(M2,6)	5	1,5	0,6	0,6	4
1130919						5
1130927						6
1130935						8
1130943						10
1130951						12
1131060	M3	6	1,8	0,8	0,7	4
1131079						5
1131087						6
1131095						8
1131109						10
1131117						12

M2,5: selon ISO 1580, M2,6: n'est pas dans DIN 85 et ISO 1580

Article#	d ₁	d ₂	k max.	n	t min.	L
1131125	M3	6	1,8	0,8	0,7	(14)
1131133						16
1131141						(18)
1131168						20
1131176						(22)
1131184						25
1131192						30
1131206						35
1131214						40
1432141						50
1432176						60
1131230	(M3,5)	7	2,1	1	0,8	5
1131249						6
1131257						8
1131265						10
1131273						12
1131303						16
1131338						20
1131354						25
1131362						30
1131370						35
1131397	M4	8	2,4	1,2	1	4
1131400						5
1131419						6
1131427						8
1131435						10
1131443						12
1131451						(14)
1131478						16
1131486						(18)
1131494						20
1131508						(22)
1131516						25
1131524						30
1131532						35
1131540						40
1131559						45
1131567						50
1432184						(55)
1432192						60
1471813						70

M2,5: selon ISO 1580, M2,6: n'est pas dans DIN 85 et ISO 1580

Article#	d ₁	d ₂	k max.	n	t min.	L
1471821	M4	8	2,4	1,2	1	80
1131575	M5	10	3	1,2	1,2	6
1131583						8
1131591						10
1131605						12
1131613						(14)
1131621						16
1131648						(18)
1131656						20
1131664						(22)
1131672						25
1131680						30
1131699						35
1131702						40
1131710						45
1131729						50
1432206						(55)
1131737						60
1370383						(65)
1131745						70
1471848						80
1471856						90
1471864						100
3056158	M6	12	3,6	1,6	1,4	6
1131753						8
1131761						10
1131788						12
1131796						(14)
1131818						16
1131826						(18)
1131834						20
1131850						25
1131869						30
1131877						35
1131885						40
1131893						45
1131907						50
1131915						60
1131923						70
1131931						80
1471872						90

M2,5: selon ISO 1580, M2,6: n'est pas dans DIN 85 et ISO 1580

Article#	d ₁	d ₂	k max.	n	t min.	L
1471880	M6	12	3,6	1,6	1,4	100
1120239	(M8)	16	4,8	2	1,9	10
1120247						12
1120263						16
1120298						20
1120328						25
1120409						30
1120425						35
1120441						40
1120468						45
1120476						50
1120484						60
1120492						70
1120506						80
1471899						90