



MPO Fibre Cable 12 Cores OM4

Technical Features

MPO/PC female to female

Multimode OM4 50/125 μm

LSZH: 3.0 mm


12 cores fiber cable

Polarity Type B

Cable: Erika violet

Test report included

Technical Drawings

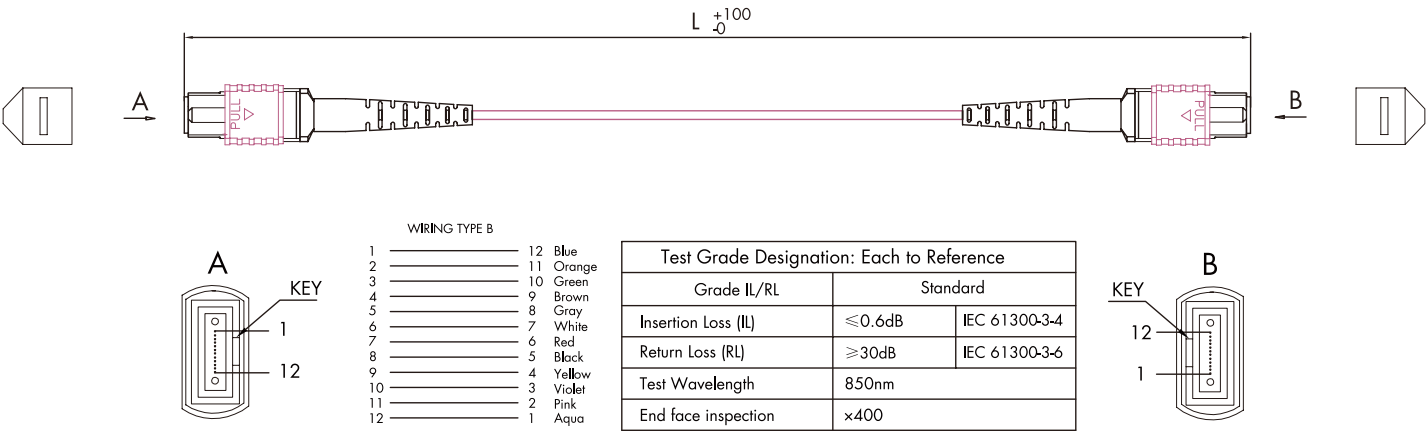

Art. No.	Length	EAN Code	Art. No.	Length	EAN Code
FM7LC01	1 m	4052792079371	FM7LC07	7.5 m	4052792079418
FM7LC02	2 m	4052792079388	FM7LC10	10 m	4052792079425
FM7LC03	3 m	4052792079395	FM7LC15	15 m	4052792079432
FM7LC05	5 m	4052792079401	FM7LC20	20 m	4052792079449

Package Content

1 x MPO Fibre Cable 12 Cores OM4

Packaging Information

Art-No.	Packing Dimension	Packing Weight	Carton Dimension	Carton Q'ty	Carton Weight
FM7LC01	150 x 150 x 20 mm	0.013 kg	450 x 450 x 250 mm	600 pcs	8.3 kg
FM7LC02	180 x 180 x 20 mm	0.022 kg	450 x 450 x 250 mm	500 pcs	11.3 kg
FM7LC03	180 x 180 x 30 mm	0.029 kg	450 x 450 x 250 mm	400 pcs	12.3 kg
FM7LC05	180 x 180 x 30 mm	0.046 kg	450 x 450 x 250 mm	320 pcs	15.3 kg
FM7LC07	180 x 180 x 40 mm	0.068 kg	450 x 450 x 250 mm	200 pcs	14.2 kg
FM7LC10	180 x 180 x 60 mm	0.088 kg	450 x 450 x 250 mm	160 pcs	14.7 kg
FM7LC15	230 x 230 x 70 mm	0.130 kg	450 x 450 x 250 mm	100 pcs	13.6 kg
FM7LC20	230 x 230 x 80 mm	0.170 kg	450 x 450 x 250 mm	80 pcs	14.2 kg

