




DIN 966 A

~ISO 7047

4.8

Norma ritirata

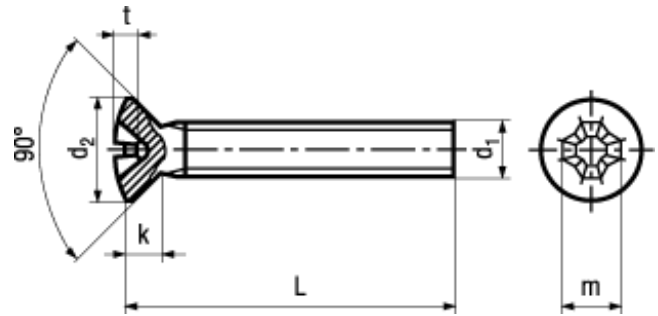

BN 392

Viti a testa svasata con calotta

ed impronta a croce Phillips forma H

Acciaio 4.8

zincato bianco

- ~UNI 7689
- ~ČSN 021156

[3D Cadenas](#)

Tutte le misure con filettatura quasi completa

Article#	d ₁	d ₂ max.	k max.		m~	t min.	t max.	L
3056392	M2	3,8	1,2	1	2,5	1,1	1,4	3
1135821								4
1135848								5
1135856								6
1135864								8
3056394								10
3056396	M2,5	4,7	1,5	1	2,7	1,3	1,6	4
1158392								5
1158406								6
1158414								8
1158422								10
1158430								12
3056397	M3	5,6	1,65	1	3,1	1,7	2	4
1158449								5
1158457								6
1158465								8
1158473								10
1158481								12
1158503								(14)
1158511								16
1158538								(18)
1158546								20
1158562								25
1158570								30
1471651								35
1471678								40

Article#	d ₁	d ₂ max.	k max.		m~	t min.	t max.	L
1471686	M3	5,6	1,65	1	3,1	1,7	2	45
3056398	M4	7,5	2,2	2	4,5	2,04	2,54	5
1158708								6
1158716								8
1158724								10
1158732								12
1158740								(14)
1158759								16
1158767								(18)
1158775								20
1158791								25
1158805								30
1158813								35
1158821								40
1471716								50
3056399	M5	9,2	2,5	2	5,3	2,77	3,27	6
1158848								8
1158856								10
1158864								12
1158872								(14)
1158880								16
1158902								20
1158929								25
1158937								30
1158945								35
1158953								40
1158961								45
1158988								50
1471759								60
1471767								70
1471775								80
3056400	M6	11	3	3	6,8	3,03	3,53	8
1158996								10
1159003								12
1159011								(14)
1159038								16
1159046								(18)
1159054								20
1159070								25
1159089								30
1159097								35

Article#	d ₁	d ₂ max.	k max.		m~	t min.	t max.	L
1159100	M6	11	3	3	6,8	3,03	3,53	40
1159119								45
1159127								50
1471783								60
1471791								70
1471805								80
1124994	M8	14,5	4	4	9	4,18	4,68	16
1125966								20
1126113								25
1126431								30
1127020								35
1127039								40