



886E

Product no.: 886E

Side cutter - tapered head



The jaws of the cutter have straight edges and taper to a point. This head shape allows access to difficult to reach areas but reduces the cutting capacity in comparison to the same size oval head cutter.



source images

The Perfect Cut - Strong, sharp and precise, every time


The Weller Erem Series 800 Maxi is a range of maxi-sized precision cutters for general cutting applications in electronics to cut large wire diameters. The cutters are made from high grade tool steel with cutting edges hardened to 63-65HRC. The precision cutters have a nonreflecting surface, are ESD safe and resharpenable.

Type	Type of Cut	Cutting Capacity
------	-------------	------------------

Series 800 Maxi & 2800

mm 0,03 0,1 0,2 0,3 0,4 0,5 0,6 0,7 0,8 0,9 1,0 1,1 1,2 1,3 1,4 1,5 1,6 1,7 1,8 1,9 2,0
Inch .0001 .003 .007 .011 .015 .019 .023 .027 .031 .035 .039 .043 .047 .051 .055 .059 .062 .066 .070 .074 .078

	812N 2812N	 Semi Flush	
	822N 2822N	 Flush	
	886E 2886E	 Flush	
	884E 2884E	 Flush	

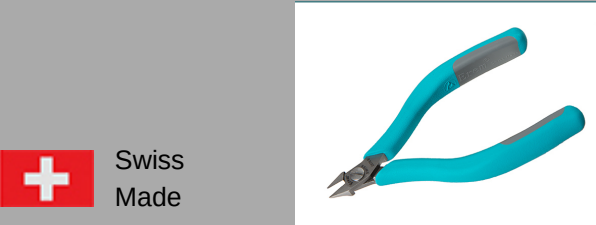



Technical Data

Length mm	120
Length of cutting edges mm	15
Head width mm	13.5
Head thickness mm	7.2
Head length mm	21
Max. cutting capability – hard wire mm	---
Weight in oz	2.998
Length of cutting edges Inches	0.590
Head width Inches	0.531
Head thickness Inches	0.284
Head length Inches	0.827
ESD-safe	on
Cut	Flush
Max. cutting capability – medium hardness mm	Ø 1,0
Max. cutting capability – copper wire mm	Ø 1,8
Length inches	4.724
Weight in g	85
Erem applications	---