


DIGITUS® Modular Patch Panel, 16-port

DN-91400

EAN 4016032280750

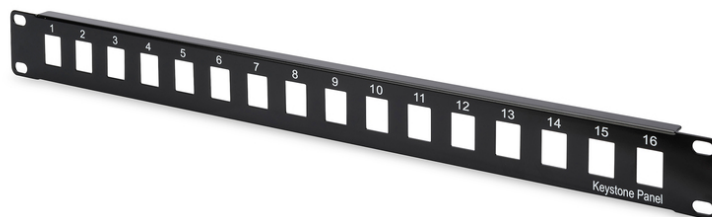

Modular Patch Panel, unshielded, 16-port blank, 1U, rack mount, black RAL 9005

The Modular Patch Panel from DIGITUS® is available as 16- or 24-port version. The 1.5 mm cold rolled c-steel provides the best storage of your Keystone Modules.

- Layout Keystone Entry: Double-row
- Area of application: 483 mm (19") cabinet
- Norms: ISO/IEC 11801 3rd Ed., EN 50173-1, EIA/TIA 568-C
- General properties:
- Suitable for 483 mm (19") cabinet mounting
- Suitable for unshielded Digitus® Keystone Modules and Couplers
- Technical properties:

- Housing material: 1.5 mm SPCC cold rolled stell sheet, powder-coated
- Material standard: EN 10 130(1991), BS 1449, NFA 36/401, DIN 1623, UNI 5866, UNE 36-086, SIS, JIS G 3141, ASTM, SAE, NFA 36/401
- Physical properties:
- Operation temperature: -20° C to +70 °C (ISO/IEC 11801, EN 50173-1, ANSI/TIA/EIA 568 C)
- Colour: Black RAL9005

Attributes

- Color: black, RAL 9005
- Ports: 16
- Units: 1

Logistics

	Number (pcs)	Weight (kg)	Depth (cm)	Width (cm)	Height (cm)	cm³
Packaging Unit Carton	64	22.02	58.00	24.00	25.00	34,800.00
Packaging Unit Inside	8	2.75	56.50	10.00	7.50	4,237.50
Packaging Unit Single	1	0.34	48.50	4.30	1.50	312.83
Net single without Packaging	1	0.25	48.50	4.30	1.50	312.83

Safety notes

- Protect product from moisture
- Avoid antistatic charging when installing the product
- Observe the specifications of the raw cable manufacturer during installation

EU responsible person

EU based economic operator ensuring the product complies with the required regulations.

ASSMANN Electronic GmbH
Auf dem Schöffel 3
Lüdenscheid, Germany

<https://www.assmann.com>
info@assmann.com