


Patch cord kat. 5E, FTP, 0.25 m

PP22-0.25M

- Perfect connection
- Foil shielded for a reliable connection
- Gold plated contacts

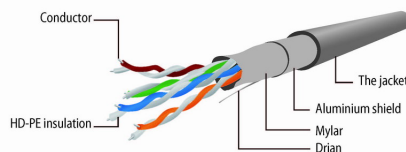

Cechy produktu

- Patch cord kat. 5E, FTP
- Połączany koncowki
- Formowane złączki

Specyfikacja

Category: Enhanced category 5
 Type: FTP (foil shielded)
 Frequency bandwidth: Max. 100 MHz
 Compliance with ANSI / TIA / EIA-568B standards
 Conductor: AWG 26 (7 x 0.15 mm wire), CCA
 Conductor insulation: HDPE 0.85 mm
 Shielding: AL foil
 LDPE filler: n/a
 Polyester tape: yes
 Drain wire: yes (7 x 0.12 mm CCA)
 Jacket material: PVC
 Jacket braiding: n/a
 Jacket outer diameter: 5.0 mm
 Length: conform item description
 Color: conform item description

Opakowanie

Ilość sztuk w kartonie	300
Objętość kartonu	0.022
Waga kartonu, kg	7.82
Wymiary opakowania:	170x120x10 mm
Wymiary kartonu DxSxW	385x310x185 mm
Kraj pochodzenia	CN
Kod kreskowy EAN	8716309074773
Kod celny	8544421000

Certyfikaty

