



BN 117 — Hex nuts ~0,8d

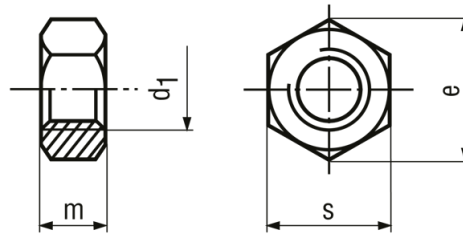

Product features	• up to M5: class 6
Standard	DIN 934 (Standard withdrawn) ~ISO 4032 ~UNI 5588 ~ČSN 021401
Material	Steel
Surface	zinc plated blue
Property class	8 (dM5 class 6)


ⓘ M10; M12; M14; M22: wrench size according to ISO on request

BN 117 — Hex nuts ~0,8d

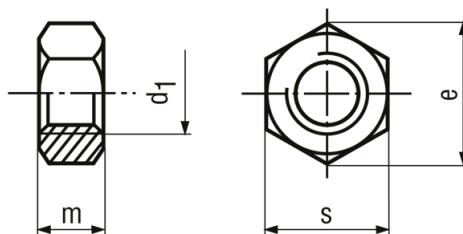

Article No.	d1	e min.	s	m max.
1874659	M3	6,01	5,5	2,4
1874667	M3	6,01	5,5	2,4
1089536	M3	6,01	5,5	2,4
1874675	M3,5	6,58	6	2,8
1874683	M3,5	6,58	6	2,8
1874691	M4	7,66	7	3,2
1874705	M4	7,66	7	3,2
1089552	M4	7,66	7	3,2
1874713	M5	8,79	8	4
1874721	M5	8,79	8	4
1089560	M5	8,79	8	4
1874748	M6	11,05	10	5
1874756	M6	11,05	10	5
1089579	M6	11,05	10	5
1874764	M7	12,12	11	5,5
1089587	M7	12,12	11	5,5
1874772	M8	14,38	13	6,5
1089595	M8	14,38	13	6,5
1874780	M10	18,9	17	8
1089609	M10	18,9	17	8
1874799	M12	21,1	19	10
1089617	M12	21,1	19	10
1874802	M14	24,49	22	11
1089625	M14	24,49	22	11

BN 117 — Hex nuts ~0,8d

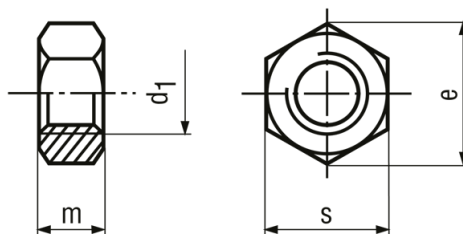

Article No.	d1	e min.	s	m max.
1874810	M16	26,75	24	13
1089633	M16	26,75	24	13
1089641	M18	29,56	27	15
1874829	M20	32,95	30	16
1089668	M20	32,95	30	16
1089676	M22	35,03	32	18
1089684	M24	39,55	36	19
1089692	M27	45,2	41	22
1089706	M30	50,85	46	24
1089714	M33	55,37	50	26
1089722	M36	60,79	55	29
5510541	M39	66,44	60	31
5503976	M42	71,3	65	34
5523246	M45	76,95	70	36
5514436	M48	82,6	75	38