


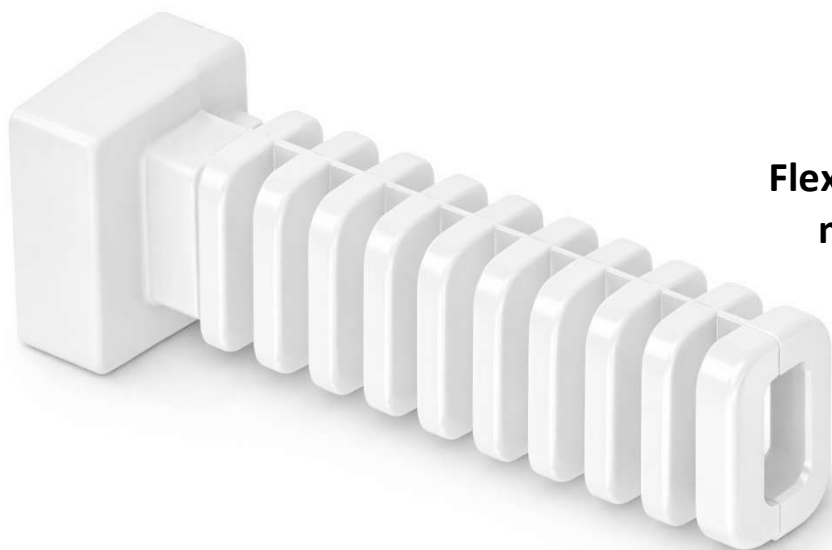

**Flexible strain relief for cables
model : F3.5x1.8/25-WH**

Dimmension

Cable cross section (A)	3.5 x 1.8 mm
Total length (F)	25mm
Working length (E)	18mm
Width (B)	10mm
Width (D)	8.2mm
Mounting hole (C)	Max 5.5 x 4.8mm
Maximum mounting wall thickness (G)	2.2mm

Other

Material

Hydrogenated styrene butadiene block copolymer (SEBS)
Hydrogenated styrene isoprene butadiene block copolymer (SEEPS)
Ethylene Propylene Diene Monomer (EPDM)
Styrene butadiene styrene block copolymer (SBS)

