


Cable USB 2.0 pin header female 2.00 mm 10 pin > 2 x USB 2.0 Type-A female panel-mount 25 cm

Description

This cable enables you to extend a USB 2.0 connection and can be used to connect various devices. The female port can be attached with two screws, e.g. to a slot bracket, a cable duct or an enclosure with the corresponding opening. This can be used to install an USB connector on an easily accessible position. The cable is most suitable for self-designed computer systems.

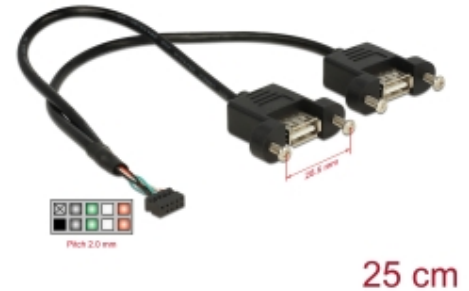

Item no. 84832

EAN: 4043619848324

Country of origin: China

Package: Zip poly bag

Technical details

- Connector:
1 x 10 pin USB 2.0 pin header female >
2 x USB 2.0 Type-A female with screw nuts for installation
- Pitch distance: 2.00 mm
- Pin 10 = Key
- Screw type: M3
- Mounting hole: ca. 17.5 x 11.5 mm, screw hole pitch ca. 28.5 mm
- Cable gauge: 28 AWG
- Cable diameter: ca. 4 mm
- Gold-plated connector
- Data transfer rate up to 480 Mb/s
- Colour: black
- Length incl. connector: ca. 25 cm

System requirements

- A free 2.00 mm USB 2.0 pin header

Package content

- USB panel-mount cable
- 4 screws

Images



General

Specification:	USB 2.0
----------------	---------

Interface

Connector 1:	1 x 10 pin USB 2.0 pin header female
Connector 2:	2 x USB 2.0 Type-A female

Technical characteristics

Data transfer rate:	480 Mbps
---------------------	----------

Physical characteristics

Pitch distance:	2.00 mm
Cable gauge:	28 AWG
Length:	25 cm
Colour:	black
Cable diameter:	4 mm

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de