

USB 5 Gbps Dual Docking Station for 2 x SATA HDD / SSD with Clone Function

Description

This HDD / SSD docking station by Delock enables an external connection of two 2.5" or 3.5" SATA HDDs / SSDs through the USB interface. This solution does not require an external enclosure since the HDD / SSD will be plugged into the docking station directly. Furthermore the clone function enables to copy the content of one HDD to another without using a PC.



Item no. 62661

EAN: 4043619626618

Country of origin: China

Package: Retail Box

Technical details

- Connectors:
 - 2 x SATA 6 Gb/s 22 pin receptacle
 - 1 x USB 5 Gbps Type-B female
 - 1 x DC jack
- Function key:
 - 1 x Clone button
 - 1 x On / Off switch
- For 2.5" and 3.5" SATA HDD / SSD
- Suitable for all SATA HDDs / SSDs up to SATA 6 Gb/s
- Data transfer rate up to 5 Gbps
- LED indicator for power, access and copy status
- Dimensions (LxWxH): ca. 149 x 114 x 61 mm
- Plug & Play

Power supply specification

- Power supply type: Euro wall power plug
- Model identifier: FJ-SW248G1203000E
- Input voltage: 100 - 240 V
- Input AC frequency: 50 / 60 Hz
- Input current: 1.5 A

- Output voltage / Output current / Output power: 12.0 V / 3.0 A / 36.0 W
- Average active efficiency: 87.7 %
- Efficiency at low load (10 %): 81.9 %
- No-load power consumption: 0.10 W
- Power supply cable length: ca. 1.5 m
- DC power connector: 5.5 x 2.5 mm
- Ground outside, plus inside


System requirements

- Linux Kernel 3.7 or above
- Mac OS 10.7 or above
- Windows Vista/Vista-64/7/7-64/8.1/8.1-64/10/10-64/11
- PC or laptop with a free USB Type-A port

Package content

- Dual Docking Station
- USB 5 Gbps cable
- External power supply 12 V / 3 A
- User manual

Images

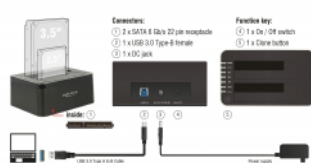

General

Function:	Clone Function
Suitable for data medium:	2.5" 3.5" SSD or HDD
Supported operating system:	Linux Kernel 3.7 or above Mac OS 10.10 or above Windows 10 32-Bit Windows 10 64-Bit Windows 7 32-Bit Windows 7 64-Bit Windows 8.1 32-Bit Windows 8.1 64-Bit Windows Vista 32-bit Windows Vista 64-bit Windows 11

Interface

External:	1 x DC jack 1 x USB 5 Gbps Type-B female
Internal:	2 x SATA 22 Pin Buchse

Physical characteristics

Housing material:	Plastic
Length:	149 mm
Width:	114 mm
Height:	61 mm
Colour:	black

Power supply

Power supply type:	Power supply specification Euro wall power supply
--------------------	---

Model identifier:	Power supply specification FJ-SW248G1203000E
Input voltage:	Power supply specification 100 - 240 V
Input AC frequency:	Power supply specification 50 / 60 Hz
Input current:	Power supply specification 1.5 A
Output voltage / Output current / Output power:	Power supply specification 12.0 V / 3.0 A / 36.0 W
Average active efficiency:	Power supply specification 87.7 %
Efficiency at low load (10 %):	Power supply specification 81.9 %
No-load power consumption:	Power supply specification 0.10 W
Power supply connector:	Power supply specification DC plug 5.5 mm x 2.5 mm Ground outside, plus inside
Cable length of power supply:	Power supply specification 1.5 m

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de