

USB 10 Gbps Extension Cable USB Type-C™ male to female 1,5 m 4K PD 60 W

Description

This USB cable by Delock allows the extension of a USB Type-C™ connection.



Item no. 85534

EAN: 4043619855346

Country of origin: China

Package: Poly bag

Technical details

- Connectors:
 - 1 x USB 10 Gbps USB Type-C™ male
 - 1 x USB 10 Gbps USB Type-C™ female
- Cable gauge:
 - 32 AWG data line
 - 24 AWG power line
- Output current: up to 3 A
- Cable diameter: ca. 4.5 mm
- Data transfer rate up to USB 10 Gbps
- Supports HDR
- Supports HDCP
- Supports DisplayPort Alt Mode
- USB Power Delivery (USB PD 3.0) support up to 60 watt
- Colour: black
- Length incl. connectors: ca. 1.5 m


System requirements

- PC or laptop with a free USB Type-C™ port

Package content

- USB cable

Images

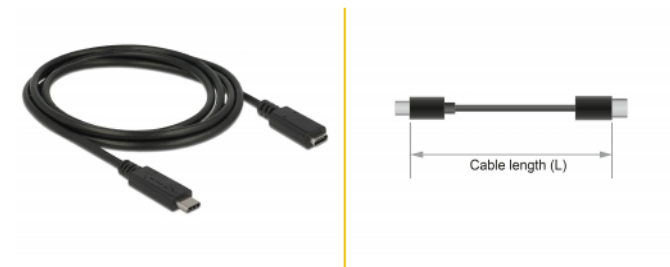

General

Specification:	HDR USB 10 Gbps USB Power Delivery 3.0
----------------	--

Interface

Connector 1:	1 x USB Type-C™ male
Connector 2:	1 x USB Type-C™ female

Technical characteristics

Data transfer rate:	10 Gbps
Maximum power:	60 W
Maximum current:	3 A

Physical characteristics

Cable gauge:	32 AWG data line 24 AWG power line
Length:	1.5 m
Colour:	black

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de