



BETA 1150BM
combination pliers bright
chrome-plated, bi-material
handles

Certifications and Standards

= ISO 5746

Features

Universal pliers with large effect

OFF-CENTRE PIVOT

Reduces the physical effort required, improving work efficiency and reducing fatigue, even with prolonged use.

CHROME-PLATED FINISH

Maximum resistance to corrosion and wear, for a tool that is always flawless and easy to clean, even after intensive use.

BI-MATERIAL HANDLES

Secure grip and superior comfort, even under prolonged use, for optimal control and maximum safety.



VERSATILITY


Knurled jaws for a secure grip and integrated cutting edges near the fulcrum, ideal for clamping and precise cutting of wires and cables with minimum effort.



OPTIMAL COMFORT

Bi-material handles for a firm and comfortable grip in every use.

Dimensions

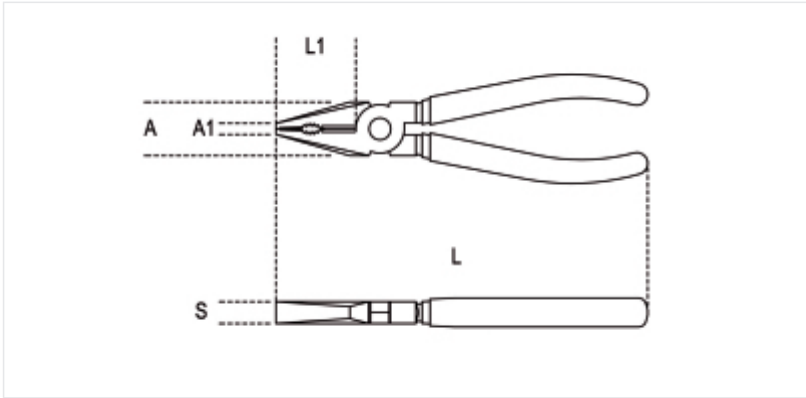

Certifications and Standards

ISO 5746

Coded items

	Art.	L mm	L1 mm	 mm	A mm	A1 mm	S mm	 g
011500146	1150BM 160	160	42	1,6	22,0	5,6	10,0	200
011500148	1150BM 180	180	46	1,8	25,0	6,3	11,0	275
011500150	1150BM 200	200	50	2,0	27,0	7,1	11,5	310
011500152	1150BM 220	220	50	2,0	27,0	7,1	11,8	400

Scan the QR Code to access the web tab
Specs, media and documentation in one click.

