

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0731000259

Status:

Active

Overview:

SMB RF Connectors

Description:

75 Ohms, SMB PCB Jack Receptacle, Right-Angle, Gold (Au) Flash Plated Body, Tray

Documents:

[Drawing \(PDF\)](#)

[Product Specification PS-73598-0104-001 \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family

Series

Overview

Product Name

Style

Taxonomy

Type

UPC

Wire/Cable Type

RF/Coax Connectors

73404

SMB RF Connectors

SMB

PCB

RF / Coaxial Connectors

Subminiature

800753680555

N/A

Physical

Gender

Keying to Mating Part

Net Weight

Orientation

PCB Mounting

PCB Thickness - Recommended

Packaging Type

Panel Mount

Panel Mount Method

Reverse Polar

Jack

None

2.204/g

Right Angle

Through Hole

2.40mm

Tray

No

N/A

No

Electrical

Frequency

Impedance

Power / Voltage

4 GHz

75Ω

VOLTAGE: 335 Vrms@Sea Level

Solder Process Data

Duration at Max. Process Temperature (seconds)

Lead-freeProcess Capability

Max. Cycles at Max. Process Temperature

Process Temperature max. C

010

SMC&WAVE

001

260

Material Info


Reference - Drawing Numbers

Product Specification

Sales Drawing

PS-73598-0104-001

SD-73100-0259-001

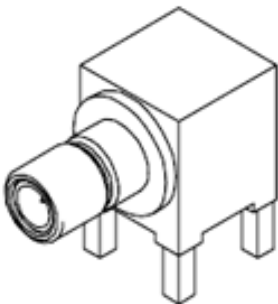

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per - D(2020)9139-DC (19 Jan 2021)

Lead

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

50 Image

Not Relevant

Not Contained

Search Parts in this Series

73404 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION