

MILAN S.r.l. a socio Unico


Head Office - Export Department
Viale Europa, 74
20047 Cusago (MI) Italy
Tel. +39 02 9039.4556 - 4158
www.taskercables.com

Ufficio Commerciale e Distribuzione
Viale Europa, 72 Strada F12
20047 Cusago (MI) Italy
Tel. +39 02 9039.0037 - 0059
www.tasker.it

Capitale Sociale € 100.000,00 i.v.
Cod. Fisc. e RIVA/VAT Nr. IT 03835660154
RE.A. MI 975732 Reg. Imprese MI 178864-5179-14
PEC: taskerpec@legalmail.it

Technical Datasheet **RoHS₃**

tasker® C239 TN – 2x2,50 mm² - Transparent Flat Cable

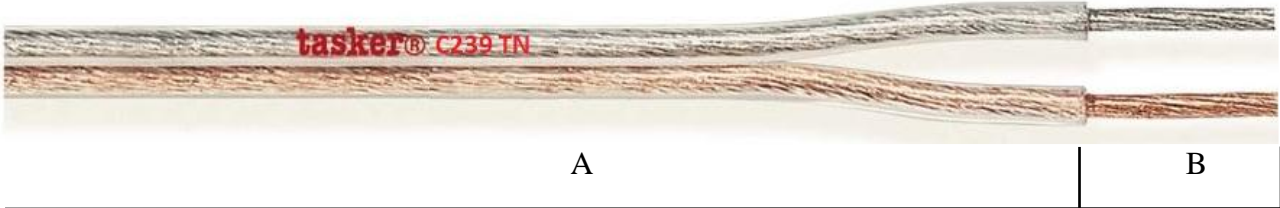

CATEGORY Flexible Audio Cable
APPLICATIONS Speaker and Home Theatre installation

- A:** Transparent **PVC** Sheath.
Outer Dimension 3,60x7,40 (±0,20) mm.
- B:** One conductor of O.F.C. tinned copper and one of O.F.C. Red Copper.
Stranded Formation 50x0,25 mm.
Nominal cross section 2x2,50 mm².

MARKING tasker® C239TN 2x2,50 mm² - O.F.C. – SPEAKER CABLE MADE IN ITALY
CUSTOM This product may be custom produced also in **L.S.Z.H.** polymer, **PE** or **PUR**.
PRODUCTION

Conductors Properties

Conductor Resistance	7,60 Ω/Km
Max Rated Voltage	49 V
Operative Temperature	-15/+70°C

USE	X	Indoor	Interno Edificio	INSTALLATION	X	Fixed	Fissa	INFORMATION	X	RoHS3 Compliant
Impiego		Outdoor Limited	Esterno Limitato	Posa	X	Restricted Mobile	Mobile Limitata	Informazioni	X	Ver. A / 17.10.22
		Outdoor	Esterno			Mobile	Mobile			
		Outdoor Direct Burial	Esterno Interrato			Mobile in Drag Chain	Mobile in Catena			