

DIGITUS® Modular Patch Panel, 24-port

DN-91410

EAN 4016032280781



Modular Patch Panel, shielded 24-port, blank, 1U, rack mount, grey RAL 7035

The Modular Patch Panel from DIGITUS® is available as 16- or 24-port version. The 1.5 mm cold rolled c-steel provides the best storage of your Keystone Modules.

- Layout Keystone Entry: Straight
- Area of application: 483 mm (19") cabinet
- Norms: ISO/IEC 11801 3rd Ed., EN 50173-1, EIA/TIA 568-C
- General properties:
- Suitable for 483 mm (19") cabinet mounting
- Suitable for shielded Digitus® Keystone Modules and Couplers
- Central ground connection
- Technical properties:
- Housing material: 1.5 mm SPCC cold rolled stell sheet, powder-coated

- Material standard: EN 10 130(1991), BS 1449, NFA 36/401, DIN 1623, UNI 5866, UNE 36-086, SIS, JIS G 3141, ASTM, SAE, NFA 36/401
- Grounding bar material: Galvanized steel
- Physical properties:
- Operation temperature: -20° C to +70 °C (ISO/IEC 11801, EN 50173-1, ANSI/TIA/EIA 568 C)
- Operation temperature: -20° C to +70 °C (ISO/IEC 11801, EN 50173-1, ANSI/TIA/EIA 568 C)
- Colour: Grey RAL7035



Attributes

- Color: light grey, RAL 7035
- Ports: 24
- Units: 1

Logistics

	Number (pcs)	Weight (kg)	Depth (cm)	Width (cm)	Height (cm)	cm³
Packaging Unit Carton	15	13.02	58.00	53.00	24.00	73,776.00
Packaging Unit Inside	1	0.87	7.30	56.50	10.00	4,124.50
Packaging Unit Single	1	0.87	7.30	56.50	10.00	4,124.50
Net single without Packaging	1	0.77	7.30	56.50	10.00	4,124.50

More images:

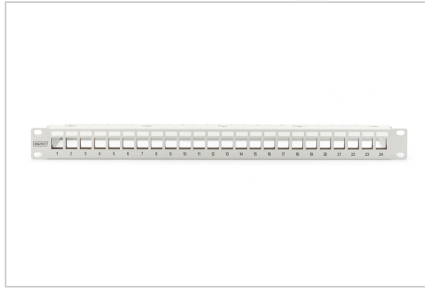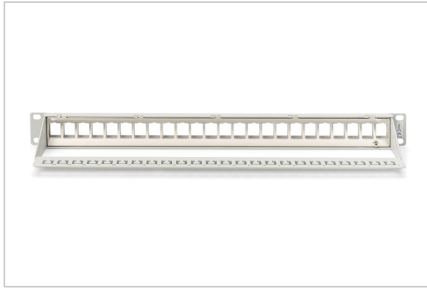

Safety notes

- Protect product from moisture
- Avoid antistatic charging when installing the product
- Observe the specifications of the raw cable manufacturer during installation

EU responsible person

EU based economic operator ensuring the product complies with the required regulations.

ASSMANN Electronic GmbH
Auf dem Schüffel 3
Lüdenscheid, Germany
<https://www.assmann.com>
info@assmann.com