


PX0477/C/C/3M00 Datasheet

 [View Product Page](#)

**Product Name // 400 Series USB-C Cable Assembly, Flex
USB-C To USB-C, 3m**

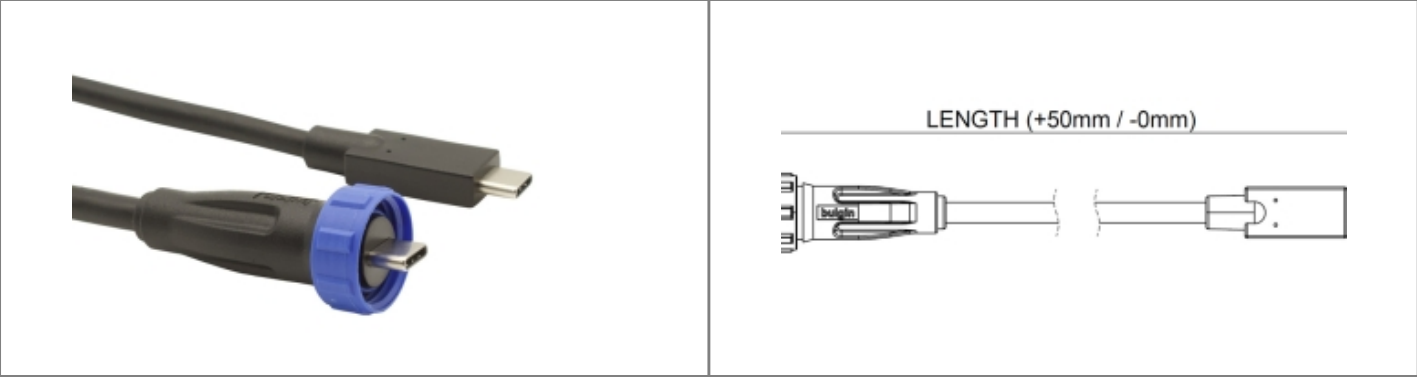

// Product Description:

- Overmoulded C-Type USB 3.2 Gen 2 Cable
- Standard USB Type C plug to Sealed C-Type USB plug
- Flex USB-C end sealed to IP68 when mated with compatible connector
- 3m cable length
- 10Gbps transfer speed, 60W charging
- PX0485 Sealing Cap available separately to maintain IP rating of unmated connectors
- Mates with PX0472 and PX0473 panel mount connectors

// General Information:

Product Display Title:	IP-sealed 'C' type to Standard 'C' type USB, 3m of Cable
Product Family:	Circular Data Connectors
Product Series:	400 Data Connectors
Body Material:	PVC/Nylon
Body Material Type:	Plastic Body
Cable Length:	3m
Contact Type:	Plug Contact
Coupling Type:	Screw
Flamability Rating:	UL94V-0
Function:	Flex to Standard Connector Double-Ended Cable
Ip Rating:	IP67, IP68
Max Operating Temperature:	+70°C
Min Operating Temperature:	-35°C
Number Of Contacts:	24 Contacts

// Product PDF Links



// Product 3D CAD Model Links



Have a question or project enquiry
you'd like to talk to us about?



[Click Here To Contact Us](#)