



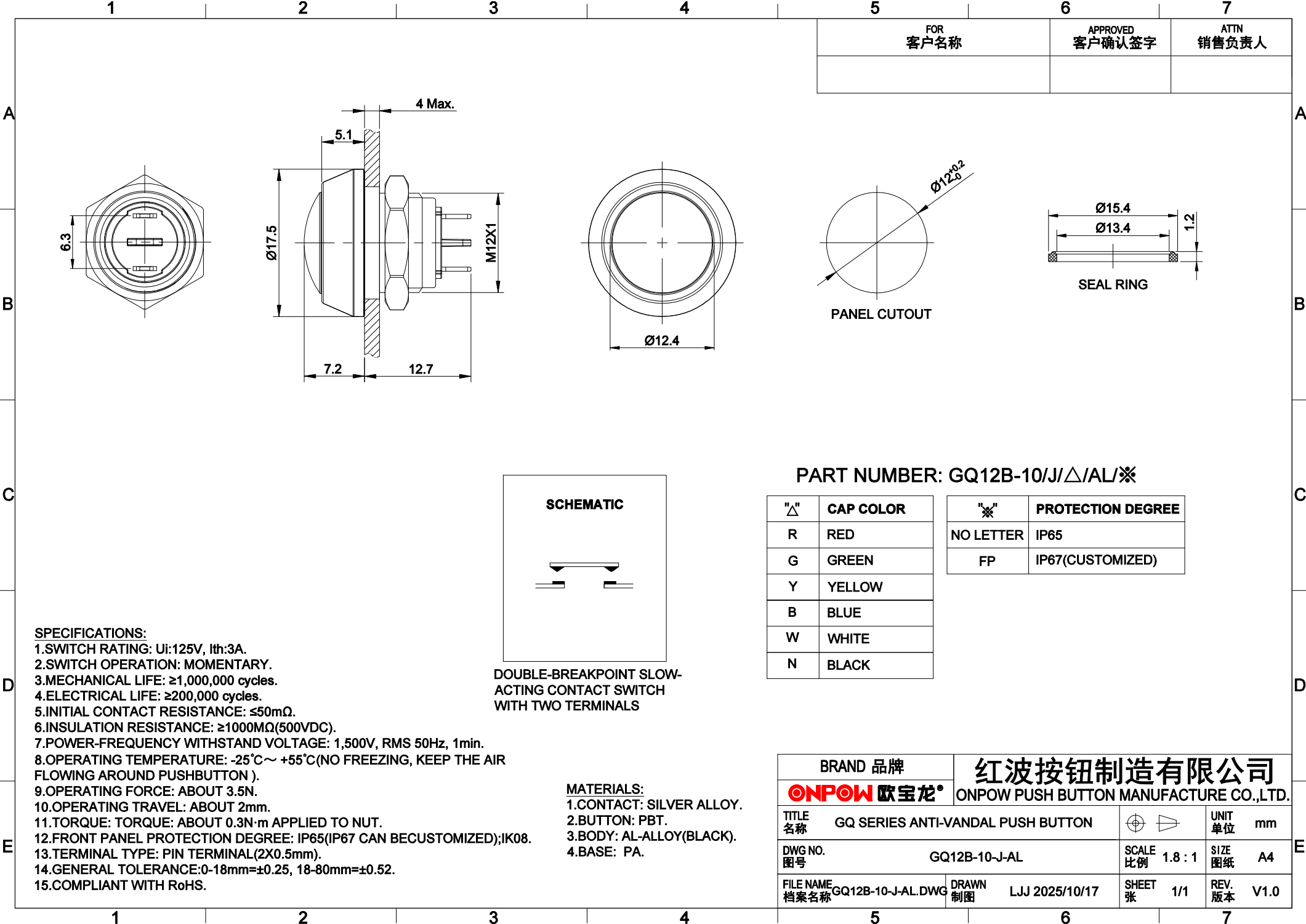


FOR 客户名称	APPROVED 客户确认签字	ATTN 销售负责人

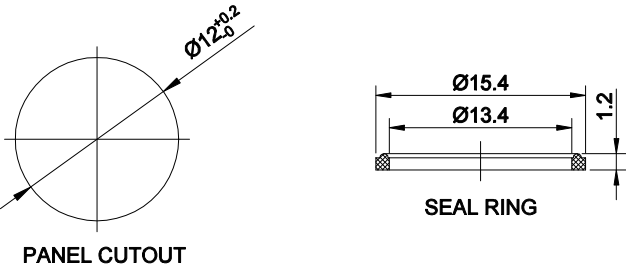

PART NUMBER: GQ12B-10/J/△/AL/※

"△"	CAP COLOR	"※"	PROTECTION DEGREE
R	RED	NO LETTER	IP65
G	GREEN	FP	IP67(CUSTOMIZED)
Y	YELLOW		
B	BLUE		
W	WHITE		
N	BLACK		

SPECIFICATIONS:
1.SWITCH RATING: Ui:125V, Ith:3A.
2.SWITCH OPERATION: MOMENTARY.
3.MECHANICAL LIFE: ≥1,000,000 cycles.
4.ELECTRICAL LIFE: ≥200,000 cycles.
5.INITIAL CONTACT RESISTANCE: ≤50mΩ.
6.INSULATION RESISTANCE: ≥1000MΩ(500VDC).
7.POWER-FREQUENCY WITHSTAND VOLTAGE: 1,500V, RMS 50Hz, 1min.
8.OPERATING TEMPERATURE: -25°C~+55°C(NO FREEZING, KEEP THE AIR FLOWING AROUND PUSHBUTTON).
9.OPERATING FORCE: ABOUT 3.5N.
10.OPERATING TRAVEL: ABOUT 2mm.
11.TORQUE: TORQUE: ABOUT 0.3N·m APPLIED TO NUT.
12.FRONT PANEL PROTECTION DEGREE: IP65(IP67 CAN BE CUSTOMIZED);IK08.
13.TERMINAL TYPE: PIN TERMINAL(2X0.5mm).
14.GENERAL TOLERANCE:0-18mm=±0.25, 18-80mm=±0.52.
15.COMPLIANT WITH RoHS.

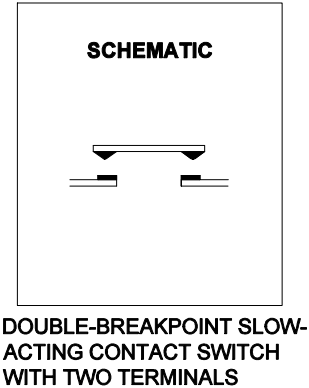

MATERIALS:
1.CONTACT: SILVER ALLOY.
2.BUTTON: PBT.
3.BODY: AL-ALLOY(BLACK).
4.BASE: PA.

BRAND 品牌		红波按钮制造有限公司			
ONPOW 欧宝龙®		ONPOW PUSH BUTTON MANUFACTURE CO.,LTD.			
TITLE 名称	GQ SERIES ANTI-VANDAL PUSH BUTTON			UNIT 单位	mm
DWG NO. 图号	GQ12B-10-J-AL			SCALE 比例	1.8 : 1
FILE NAME 档案名称	GQ12B-10-J-AL.DWG	DRAWN 制图	LJJ 2025/10/17	SHEET 张	1/1
				REV. 版本	V1.0