


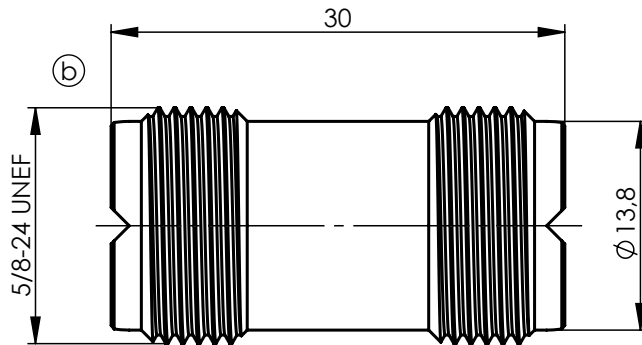

Mechanical characteristics
interface dimensions acc. to

Mechanische Eigenschaften
Steckgesicht nach

IEC 60169-12

Components
center contact
other metal parts
insulator

Bauteile
Innenkontakt
sonstige Metallteile
Isolierung

Materials / Material
brass / Messing
brass / Messing
PTFE

Finish / Oberfläche
gold plated / vergoldet
nickel plated / vernickelt

(b)

Electrical characteristics
impedance
frequency
voltage proof
contact resistance
center contact
outer contact

Elektrische Eigenschaften
Wellenwiderstand
Frequenz
Prüfspannung
Durchgangswiderstand
Innenkontakt
Außenkontakt

~50 Ω
0-200 MHz
2 kV_{eff} / 50 Hz


≤ 5 mΩ
≤ 5 mΩ

M 1:1

Environmental
operating temp.
RoHS compliant

Umgebung
Betriebstemperatur
RoHS konform

-20°C / +100°C
2011/65/EU

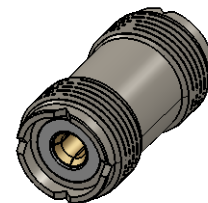

Änd./ rev. index	Änderungs-Nr. / revision code	Datum/ date	Name/ name	Datum/ date	Name/ name	Gewicht/ weight [g]
			gez./ drawn	23.04.2018	MA	
			gepr./ appr.	24.04.2018	HR	ca./approx.
			Maßstab/ scale	Benennung/ title		
			2:1 (1:1)	UHF Adapt str f-f UHF Adapt str f-f		
			untol. Maße/ dim. without tolerances according to	Unterl./ doc. type	Materialnr./ material no.	
				CUG	100024347	
			Ersatz für/ replaces	PDM Nr./ pdm no. J01042A0637		
				Maße/ dimensions: mm		
				Original : DIN A4		
				Blatt/ sheet 1 von/ of 1		

