

USB 5 Gbps Port Replicator

Description

This Delock port replicator can be connected to a single USB port of your computer and expands your system by several interfaces, like USB, audio, Gigabit Ethernet, DVI and HDMI. The DVI and HDMI ports enable the connection of two additional monitors. The port replicator supports a HD resolution of up to 2048 x 1152.

Extended screen by Displaylink

Due to the Displaylink graphics chipset it is possible to use mirrored and extended screen functions on Windows and Mac OS operating systems.



Item no. 87568

EAN: 4043619875689

Country of origin: China

Package: Retail Box

Technical details

- Connectors:
 - front side:
 - 2 x USB 5 Gbps Type-A female
 - 1 x microphone 3.5 mm stereo jack
 - 1 x speaker 3.5 mm stereo jack
 - back side:
 - 1 x USB 5 Gbps Type-B downstream port
 - 1 x DC 5 V power connector
 - 1 x HDMI female
 - 1 x DVI-I (Dual Link) 24+5 female
 - 1 x Gigabit LAN 10/100/1000 Mbps RJ45 jack
 - 4 x USB 2.0 Type-A female
- HDMI and DVI ports supports function: extended and mirror with a resolution up to 2048 x 1152 (depends on the monitor and the existing graphics card)
- Hot Plug

Power supply specification

- Wall power supply
- Input: AC 100 ~ 240 V / 50 ~ 60 Hz / 0.8 A
- Output: 5 V / 4 A
- Ground outside, plus inside
- Dimensions:

inside: $\varnothing$ ca. 1.7 mm
outside: $\varnothing$ ca. 4.75 mm
length: ca. 9.5 mm


System requirements

- Mac Lion 10.7.4 or above
- Windows XP/Vista/Vista-64/7/7-64/8.1/8.1-64/10/10-64/11
- PC or laptop with a free USB Type-A port
- 1.6 GHz CPU or above
- Minimum 30 MB free HDD space

Package content

- USB 5 Gbps Port Replicator
- USB 5 Gbps cable
- External power supply
- Driver CD
- User manual

Images

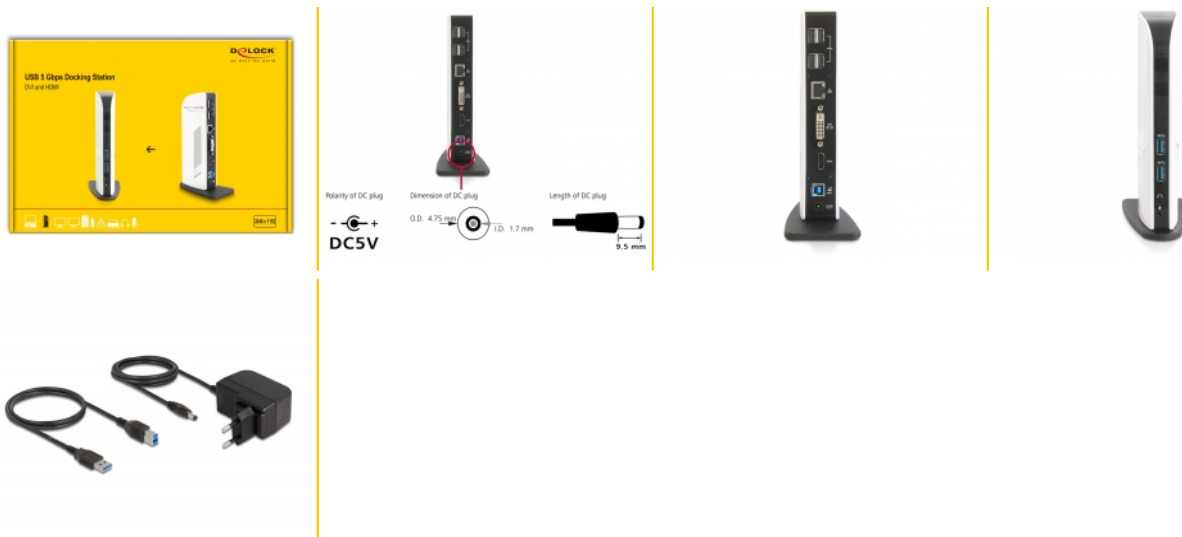

General

Function:	Hot Plug
Supported operating system:	Mac OS 10.10 or above Windows 10 32-Bit Windows 10 64-Bit Windows 7 32-Bit Windows 7 64-Bit Windows 8.1 32-Bit Windows 8.1 64-Bit Windows Vista 32-bit Windows Vista 64-bit Windows XP 32-bit Windows XP 64-bit Windows 11

Technical characteristics

Maximum screen resolution:	2048 x 1152 @ 60 Hz
----------------------------	---------------------

Physical characteristics

Colour:	white
---------	-------

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de

