


TIE10 RoundDowel

Round Dowel Clamp Ø6–Ø16 mm

- ROUND PROFILE
- DIRECT FIXING
- PE MATERIAL
- Ø6–Ø16 MM
- 2 COLOURS
- ROHS COMPLIANT

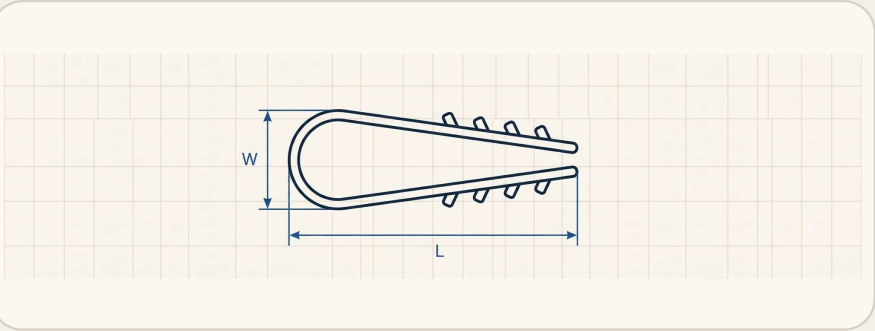

Technical specification

Material	Polyethylene PE
Colours	Black / White
Available sizes	Ø6 / Ø8 / Ø10 / Ø12 / Ø16 mm
Working temperature	-15 °C to +80 °C
Installation temperature	-10 °C to +60 °C
Resistant to	Aqueous solutions of salts, acids and alkalis

Range & item codes

ITEM CODE	PRODUCT	COLOUR	PCS/PACK	PCS/CARTON
TTDR06B	Round Dowel Clamp Ø6 mm	Black	100	13,000
TTDR06W	Round Dowel Clamp Ø6 mm	White	100	13,000
TTDR08B	Round Dowel Clamp Ø8 mm	Black	100	7,000
TTDR08W	Round Dowel Clamp Ø8 mm	White	100	7,000
TTDR10B	Round Dowel Clamp Ø10 mm	Black	100	6,000
TTDR10W	Round Dowel Clamp Ø10 mm	White	100	6,000
TTDR12B	Round Dowel Clamp Ø12 mm	Black	100	5,000
TTDR12W	Round Dowel Clamp Ø12 mm	White	100	5,000
TTDR16B	Round Dowel Clamp Ø16 mm	Black	50	2,500
TTDR16W	Round Dowel Clamp Ø16 mm	White	50	2,500

One datasheet for all RoundDowel sizes and colour variants.