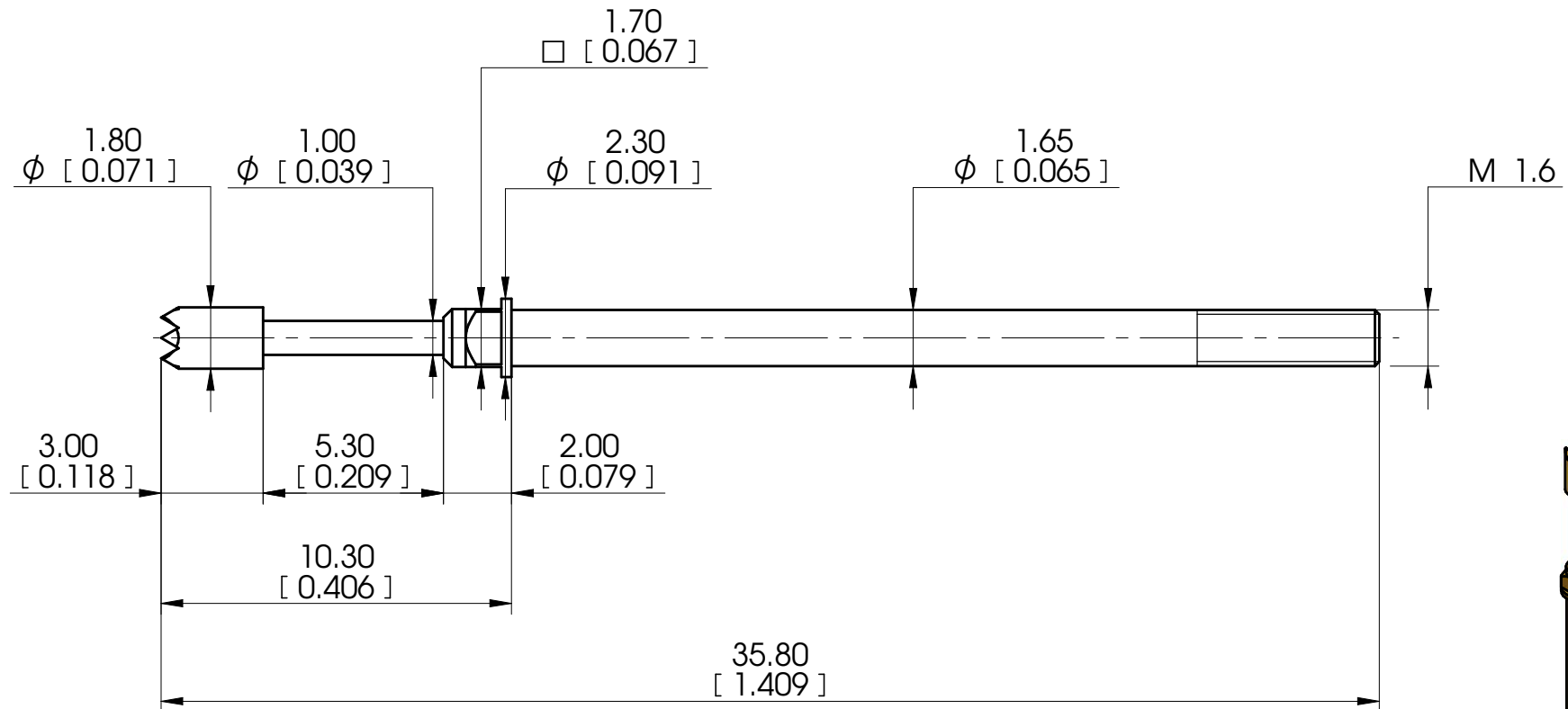


mm [inch]

**TT1005 CG06 MX**

Minimum centers: 2.54 (.100)  
 Full travel: 5.30 (.209)  
 Working travel: 4.00 (.157)  
 Current rating: 5 - 8 A  
 Probe resistance: < 20 mΩ  
 Plunger material: BeCu - Gold Plated  
 Barrel material: Brass - Gold Plated  
 Spring material: Music Wire

Operating Temperature: -30 °C up to +100 °C  
 (-22 °F up to +212 °F)

Spring force at working stroke: 1.50 N (5.4 oz)

© COPYRIGHT 2019  
 EQUIP-TEST KFT.  
 ALL RIGHTS RESERVED

This drawing, model, intellectual  
 product belongs to Equip-Test Kft.  
 Forwarding it to 3rd. party, copying it  
 or using for any other purpose  
 without the written approval of  
 Equip-Test Kft., could entail to legal  
 and criminal procedure!

|          | Name | Date        |
|----------|------|-------------|
| Designed | V.Z. | 2019.06.04. |
| Drawed   |      |             |
| Checked  |      |             |

Note

Catalog Item:

TT1005 CG06 MX

Drawing No.:



A4

SHEET 1 OF 1

