

USB Type-C™ 3.1 Docking Station 4K 30 Hz

Description

This docking station by Delock can be connected to a computer with a USB-C™ Alt-Mode or Thunderbolt™ 3 port and provides a variety of interfaces. Two monitors can be operated simultaneously at the mini DisplayPort and HDMI outputs, alternatively a single monitor at the VGA output. Three built-in USB Type-A ports allow the use of peripherals, and connections for a headset and gigabit network, as well as an SD / micro SD card reader, complete the features. With a USB-C™ power supply, laptops such as the MacBook or Chromebook can be charged during operation.



Item no. 87297

EAN: 4043619872978

Country of origin: China

Package: Retail Box

Please Note

The product is a Multi-Stream Transport (MST) hub and supports the extended desktop configuration of DisplayPort 1.2. When Mac OS is used, the same image is displayed on both ports (mirrored), it is not possible to use both ports independently of each other.

Technical details

- Connectors:
 - front side:
 - 1 x Gigabit LAN 10/100/1000 Mbps RJ45 jack
 - 1 x mini DisplayPort 20 pin female
 - 1 x HDMI-A 19 pin female
 - 1 x VGA 15 pin female
 - 1 x USB Type-C™ female (power supply)
 - back side:
 - 3 x USB 3.0 Type-A female
 - 1 x Headset 3.5 mm 4 pin jack
 - 1 x SD / SDHC / SDXC / MMC slot
 - 1 x Micro SD / SDHC / SDXC slot
 - 1 x USB Type-C™ male
- HDMI and DisplayPort ports support: extended and mirror, resolution up to 2560 x 1440 @ 60 Hz or 3840 x 2160 @ 30 Hz (depending on the system and the connected hardware)
- Functions: Mirrored or Extended (Windows only)
- VGA resolution up to 1920 x 1080 @ 60 Hz
- Transmission of audio and video signals
- Output power: max. 10 W total,
 - 1 x USB Type-A female max. 7.5 W,
 - 2 x USB Type-A female max. 5 W (combined)

- Input power: 1 x USB Type-C™ female max. 60 W
- Metal housing
- Rubber pads for safe grip and secure stand
- Cable length incl. connector: ca. 18 cm
- Colour: dark grey
- Dimensions (LxWxH): ca. 13.7 x 7.5 x 1.7 cm


System requirements

- Windows 8.1/8.1-64/10/10-64, Windows 10 Mobile, Android ex 6.0, ex Mac OS 10.9
- Device with a free USB Type-C™ port and DisplayPort alternate mode or with a free Thunderbolt™ 3 port

Package content

- USB-C™ docking station
- User manual

Images

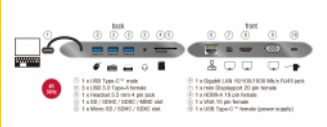

General

Specification:	DisplayPort 1.2 HDCP 1.4 HDMI 1.4 USB 5 Gbps
Supported operating system:	Android 6.0 or above Mac OS 10.9 or above Windows 10 32-Bit Windows 10 64-Bit Windows 8.1 32-Bit Windows 8.1 64-Bit

Interface

Output:	1 x 3.5 mm 4 pin stereo jack female 1 x RJ45 jack 1 x mini DisplayPort 20 pin female 1 x VGA 15 pin female 1 x SD slot 1 x Micro SD Slot 1 x HDMI-A female
Input:	1 x USB Type-C™ female (power supply) 1 x USB 5 Gbps USB Type-C™ male

Technical characteristics

Maximum screen resolution:	3840 x 2160 @ 30 Hz
Signal transmission:	video audio
Voltage supply:	USB bus powered 1 x USB Type-C™ Power Delivery female (optional for power supply)

Physical characteristics

Cable length incl. connectors:	18 cm
Colour:	dark grey

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de