


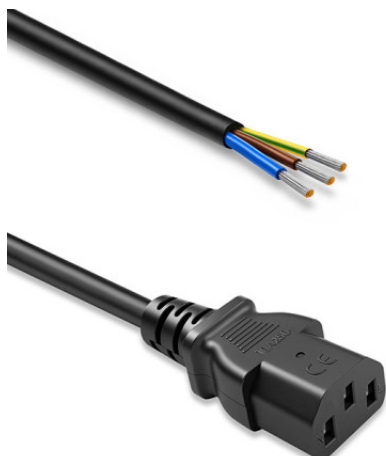


Qoltec IEC C13 Power cable | stripped and soldered | Pure copper Cu | 3x0.75mm | 0.5m

Product code: 54614

The Qoltec IEC C13 power cable has been designed to provide stable and safe power supply to electronic devices used both at home and in the office environment. The IEC standard makes the cable fully compatible with a wide range of computer equipment and professional IT installations. The use of bare copper (BC) wires guarantees very good electrical conductivity, low energy losses and reliable operation of connected devices.


RELIABILITY AT HOME, IN THE OFFICE AND IN PROFESSIONAL ENVIRONMENTS

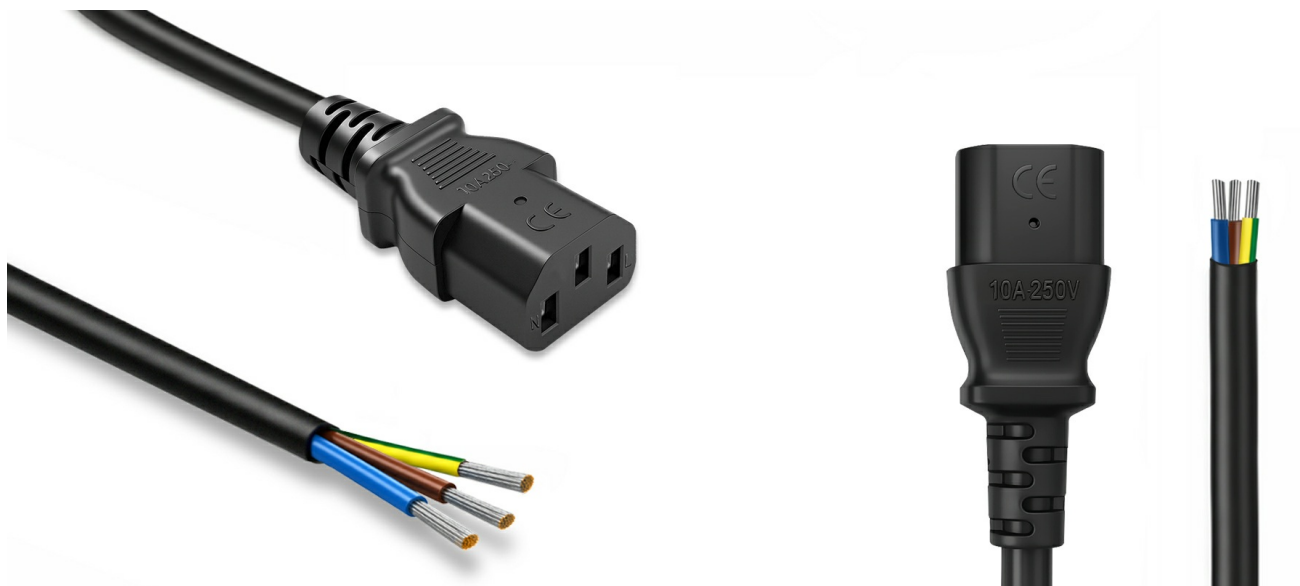

IEC C13 power cable designed for home, office and installation applications

The cable is equipped with a standard IEC C13 plug used in IT devices (computers, UPS, monitors, servers), while the other end of the cable is terminated with insulated wires, allowing for individual connection to the electrical installation or mains plug. The solution is dedicated to installers, service technicians and users who require flexible power supply options for their devices, both in home offices and professional environments.

THE IDEAL POWER SUPPLY SOLUTION

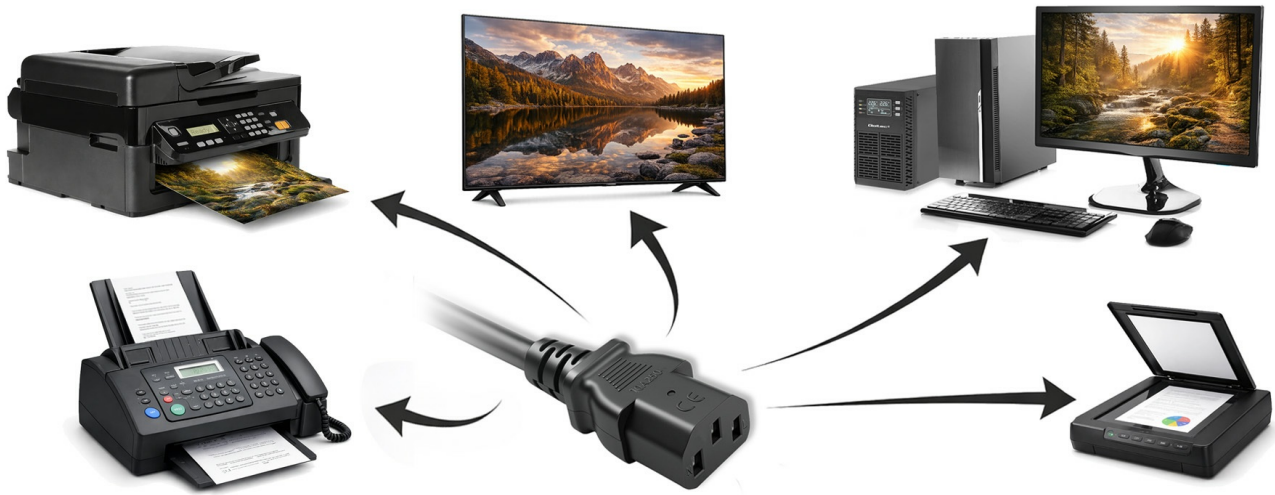


IEC C13 cable designed for powering computers, monitors, printers and other office equipment
The C13 power cable is the ideal solution for powering a wide range of devices equipped with an IEC C14 socket, such as:

- - desktop computers,
- - monitors,
- - printers,
- - television,
- - UPS emergency power supply,
- - office equipment (fax, scanner).

This solution is intended for installers and individuals undertaking their own power supply projects, where it is necessary to adapt the connector to a specific application.

HIGH QUALITY YOU CAN RELY ON EVERY DAY

Cross-section conductor $3 \times 0.75 \text{ mm}^2$

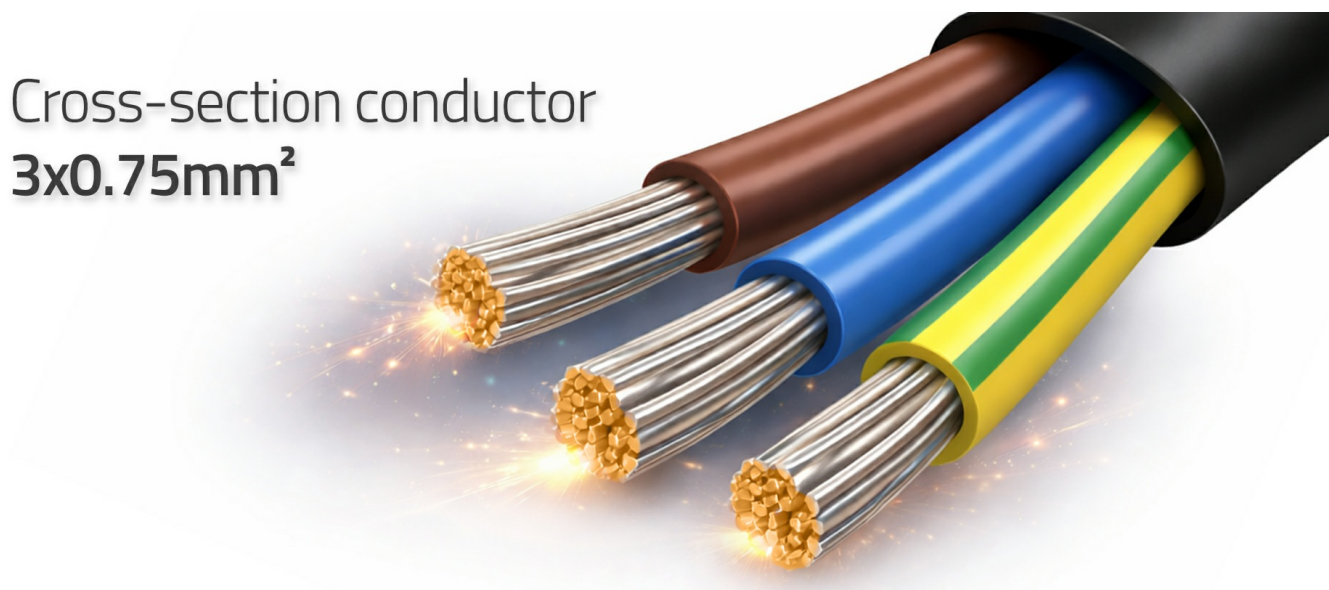

H05VV-F power cable standard, PVC insulation, copper conductors

The exceptional quality of this cable, which complies with the **H05VV-F standard**, guarantees durability and safety, even with intensive use. **Solid insulation made of polyvinyl chloride (PVC) and three high-quality copper multi-wire conductors ensure a stable flow of energy.** The appropriately selected **cable length of 0.5 m** allows for convenient connection of devices even in less accessible places, ensuring optimal range without the need for extension cords.

TRUST CONFIRMED BY WARRANTY



2-year product warranty

Looking for high quality in the products you buy? **Our solutions will meet your expectations.** Each of our power cables comes with a 24-month warranty from the date of purchase.

TECHNICAL DATA

Producer	Qoltec
Type	Power cable
Plug type	IEC C13
Output current	10A 250~
Standard of cable	H05VV-F
Conductor cross-sectional area	3 * 0.75 mm
Insulating material	PVC
Application	All electrical devices with a compatible socket.
Usage	- Desktop computers - Monitors - Printers - Television - UPS emergency power supply - Office equipment (fax, scanner)
OTHER PARAMETERS	
Colour	Black
Working temperature	-20 C ~ +60 C
Cable length	0.5m
Package	Polybag
Package contents	1 x power cable
Package depth / length [mm]	270
Package width [mm]	110
Package height [mm]	25
Net weight [kg]	0.054
Gross weight [kg]	0.056
Warranty	24 months
EAN code	5901878546148