



Connecting cable with plug

ASTAH050MSS0005H05

Please see the technical note under "Downloads"



| Application                                                     |      |                                                                                |
|-----------------------------------------------------------------|------|--------------------------------------------------------------------------------|
| Special feature                                                 |      | Free from silicone; Halogen-free; Gold-plated contacts; Drag chain suitability |
| Free from silicone                                              |      | yes                                                                            |
| Electrical data                                                 |      |                                                                                |
| Operating voltage                                               | [V]  | < 60 AC/DC                                                                     |
| Protection class                                                |      | II                                                                             |
| Max. current load total                                         | [A]  | 4                                                                              |
| Overall current rating (UL)                                     | [A]  | 3                                                                              |
| Operating conditions                                            |      |                                                                                |
| Ambient temperature                                             | [°C] | -25...90                                                                       |
| Note on ambient temperature                                     |      | cULus: ...75                                                                   |
| Ambient temperature (moving)                                    | [°C] | -25...90                                                                       |
| Note on ambient temperature (moving)                            |      | cULus: ...75                                                                   |
| Storage temperature                                             | [°C] | -25...55                                                                       |
| Storage humidity                                                | [%]  | 10...100                                                                       |
| Other climatic conditions for storage according to stated class |      | 1K22/ DIN 60721-3-1                                                            |
| Protection                                                      |      | IP 65; IP 67; IP 68; IP 69K                                                    |
| Mechanical data                                                 |      |                                                                                |
| Weight                                                          | [g]  | 177.3                                                                          |

# EVC479



## Connecting cable with plug

ASTAH050MSS0005H05

|                        |                                 |                                                                                                |
|------------------------|---------------------------------|------------------------------------------------------------------------------------------------|
| Dimensions             | [mm]                            | 30.5 x 15.5 x 36.5                                                                             |
| Materials              |                                 | housing: TPU orange                                                                            |
| Material nut           |                                 | brass, nickel-plated                                                                           |
| Drag chain suitability |                                 | yes                                                                                            |
| Drag chain suitability | bending radius for flexible use | min. 10 x cable diameter                                                                       |
|                        | travel speed                    | max. 3.3 m/s for a horizontal travel length of 5 m and max. acceleration of 5 m/s <sup>2</sup> |
|                        | bending cycles                  | > 5 Mio.                                                                                       |
|                        | torsional strain                | ± 180 °/m                                                                                      |

### Remarks


|               |                                                 |
|---------------|-------------------------------------------------|
| Notes         | Please see the technical note under "Downloads" |
| Pack quantity | 1 pcs.                                          |

### Electrical connection

Cable: 5 m, PUR, Halogen-free, black, Ø 4.6 mm; 5 x 0.34 mm<sup>2</sup>

### Electrical connection - plug

Connector: 1 x M12, angled; coding: A; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...1.5 Nm

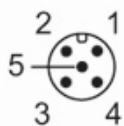

### Connection

|   |    |
|---|----|
| 1 | BN |
| 2 | WH |
| 3 | BU |
| 4 | BK |
| 5 | GY |


|      |                |
|------|----------------|
|      | Core colours : |
| BK = | black          |
| BN = | brown          |
| BU = | blue           |
| GY = | grey           |
| WH = | white          |



## Connecting cable with plug

ASTAH050MSS0005H05

### Diagrams and graphs

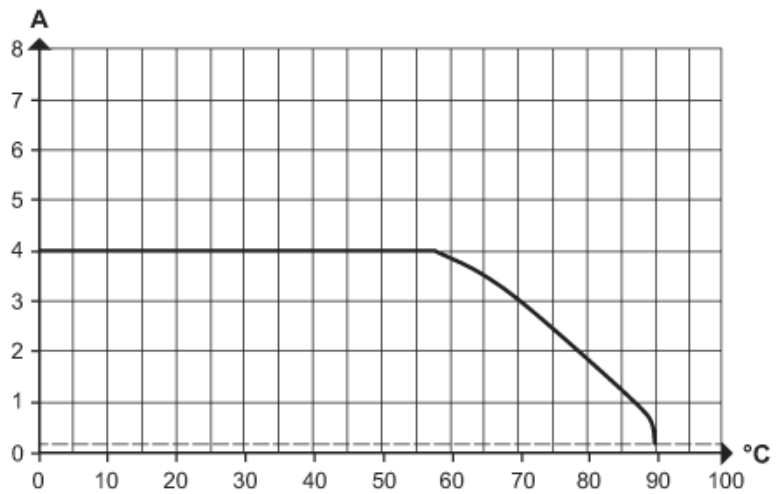

Derating  $I_{max} * 0.8$  DIN EN 60512-5-2

X Ambient temperature [°C]

Y Current [A]