

Test plug mount

Set Federelement 2x5N

Item 112863



ingun[®]

Partner for Future Technology

- Precise, low-wear contacting
- Outstanding service life
- Reliable data transmission
- Installation via floating mount
- Signal transmission via original connector plug or solder connection

INGUN SELECTION

General data

Product group:

Series:

Weight:

Min. temperature:

Max. temperature:

RoHS-compliant:

REACH-compliant:

Test plug

PS

0.01 kg [.022 lbs]

- 40 °C [- 104 °F]

+ 80 °C [+ 176 °F]

RoHS-3

no SVHC

Technical data

Stroke:

2 mm [.078 in]

Force:


5 N [17.9 ozf]

Spring force:

5 N [17.9 ozf]

Diameter:

7.5 mm [.295 in]

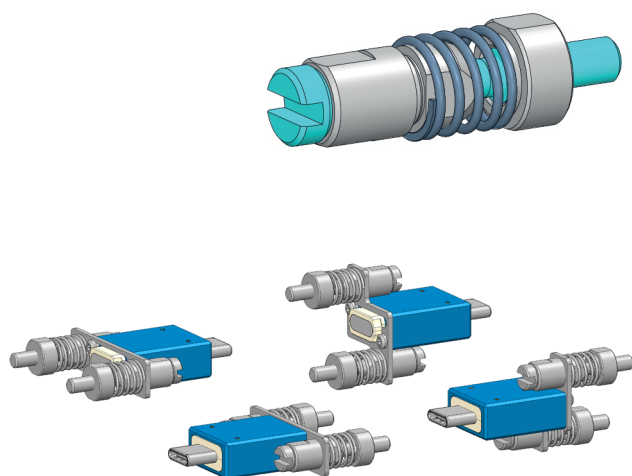

INGUN Prüfmittelbau GmbH

Max-Stromeyer-Straße 162

78467, Constance, Germany

Phone +49 7531 8105-0

Customer hotline +49 7531 8105-888

Fax +49 7531 8105-65

info@ingun.com



Prices and delivery times on request.
Technical changes reserved. 04/24_GB