


FTP Cat5e Patch cord, grey, 20 m

PP22-20M

- FTP Patch cord with moulded strain relief 50u" 8P8C plugs, 20 meters

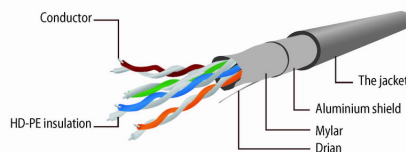

Features

- Foil shielded twisted pair patch cord

Specifications

Patch cord Enhanced category 5 FTP (shielded)
Length: according to the item
Structure: AWG 26 (7 x 0.15 mm wire), CCA
HDPE insulation of the wire: 0.85 mm
With LDPE filler: not used
With polyester tape
With aluminum foil
Drain hose: 7 x 0.12 mm CCA
PVC outer insulation: 5.0 mm
Color: according to the item
Operation up to 100 MHz

Packaging

Q'ty in crtn, pcs	20
Crtn volume, CUM	0.04
Crtn weight, kgs	9.06
Individual package size LxWxH:	320x250x50 mm
Carton size LxWxH:	400x400x250 mm
Country of origin	CN
Barcode	8716309045322
Customs code	8544421000

Certificates

