


Modular Wall Outlet 2 Port Cat.6

Description

This surface mounted box by Delock can be used as a modular outlet on the wall or in enclosures. The LSA blocks can be used with a punch down tool; alternatively, a tool-free connection of the cable is possible.

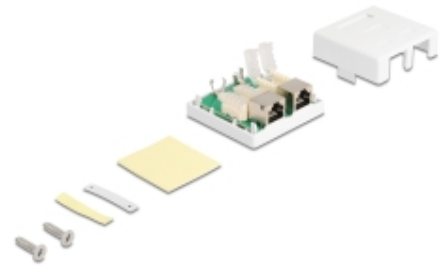

Item no. 86269

EAN: 4043619862696

Country of origin: Taiwan,
Republic of China

Package: Zip poly bag

Technical details

- Connectors:
 - external: 2 x RJ45 jack
 - internal: LSA block (toolless)
- Cable routing 180°
- Shielded (Cat.6)
- TIA-568A/B pinout
- Cable diameter up to 0.644 mm (22 – 26 AWG)
- Integrated name plate
- Color: White
- Dimensions (LxWxH): ca. 62.3 x 60 x 26 mm

Package content

- Modular Wall Outlet
- Adhesive pad, 45 x 45 mm
- 2 screws

Images



General

Suitable for conductor gauge:	22 - 26 AWG
Mounting type:	wall

Interface

External:	2 x RJ45 jack
Internal:	2 x LSA block

Technical characteristics

Category:	Cat.6
-----------	-------

Physical characteristics

Housing colour:	white
Housing material:	Plastic
Shielding:	shielded
Length:	62 mm
Width:	60 mm
Height:	26 mm

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de

