


LED tape K-HD-0830-24 8.3 W/m, IP20

Ref. K-HD-0830-24



Dimensions: Width [W]: 10 mm | Height [H]: 1.2 mm | Max run length [L]: 6 m | Cut every [C]: 33.3 mm | LED spacing [D]: 4.81 mm

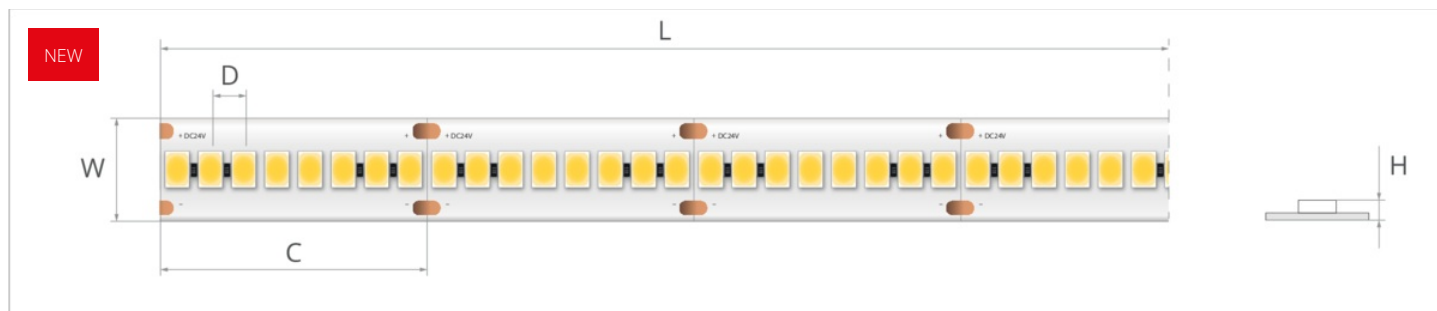

- High lighting efficacy
- High density diode placement
- Energy class: D

TECHNICAL SPECIFICATIONS

IP protection rating	20
CRI	90
LxBy	L80B50
Lifetime	75000 h
Input voltage	24 V DC
Power consumption	8.3 W/m
MacAdam's ellipse	3 SDCM
Number of LEDs per 1 m	240
Number of LEDs per cut section	7 pcs
Warranty [months]	60

Color temperature	Lumen output	Efficiency	Ref
2700 K	1355 lm/m	163 lm/W	K-HD27-0830-24
3000 K	1370 lm/m	165 lm/W	K-HD30-0830-24
4000 K	1410 lm/m	170 lm/W	K-HD40-0830-24

RELATED ACCESSORIES > RELATED LED > WHITE MONO

Name	IP protection rating	Power consumption	Ref.
LED tape K-HD-0830-24 8.3 W/m, IP20 NEW	20	8.3 W/m	K-HD27-0830-24 K-HD30-0830-24 K-HD35-0830-24 K-HD40-0830-24 K-HD50-0830-24