

DIGITUS® Single pole monitor mount, 32", 9 kg

DA-90397

EAN 4016032465140



Single Monitor Pole Mount 15-32", 8 kg (max.), black

The universal monitor column mount from DIGITUS® can hold a monitor from 15" to 32". The quick-release function also makes it easier for you to install the monitor. The VESA mount is simply pushed into the corresponding holder and fixed in place with a screw. You can easily adjust the monitor to suit your needs and can swivel, tilt or rotate the monitor itself, e.g. for portrait format monitors. Do something good for yourself and your health by optimally adjusting the monitor to your body and sitting position. In addition, the monitor cables can be neatly routed through the cable guides supplied.

Column mount for mounting monitors in any position with screw fastening

- For flat and curved displays from 15" - 32" in size
- Maximum load: 8 kg
- VESA dimensions: 75 x 75, 100 x 100
- Pivoting the VESA mount: 30°
- Inclination of the VESA mount: 30°
- Rotation of the VESA mount: 360°
- Height of the column bracket: 40 cm

- Integrated cable management
- With quick-release function for easy installation
- Recommended table top thickness: 10 - 75 mm
- Material: aluminum, plastic, steel
- Dimensions: W 11.4 x D 12.6 x H 46.2 cm
- Weight: 1.6 kg
- Color: Black, matt
- Tested & certified ergonomic product - Certified by IGR (Institute for Health and Ergonomics)

Attributes


- Monitor weight (max.): 8 kg
- Mounting method: Clamp-mount
- Number of monitors: 1
- Size of monitors: up to 32"
- VESA mount: 75x75 mm, 100x100 mm

Package contents

- Universal single monitor column mount
- Mounting accessories
- Quick guide

Logistics						
	Number (pcs)	Weight (kg)	Depth (cm)	Width (cm)	Height (cm)	cm³
Packaging Unit Carton	8	16.90	44.00	45.50	32.00	64,064.00
Packaging Unit Inside	1	2.11	21.00	44.00	7.50	6,930.00
Packaging Unit Single	1	2.11	21.00	44.00	7.50	6,930.00
Net single without Packaging	1	1.62	21.00	44.00	7.50	6,930.00

More images:

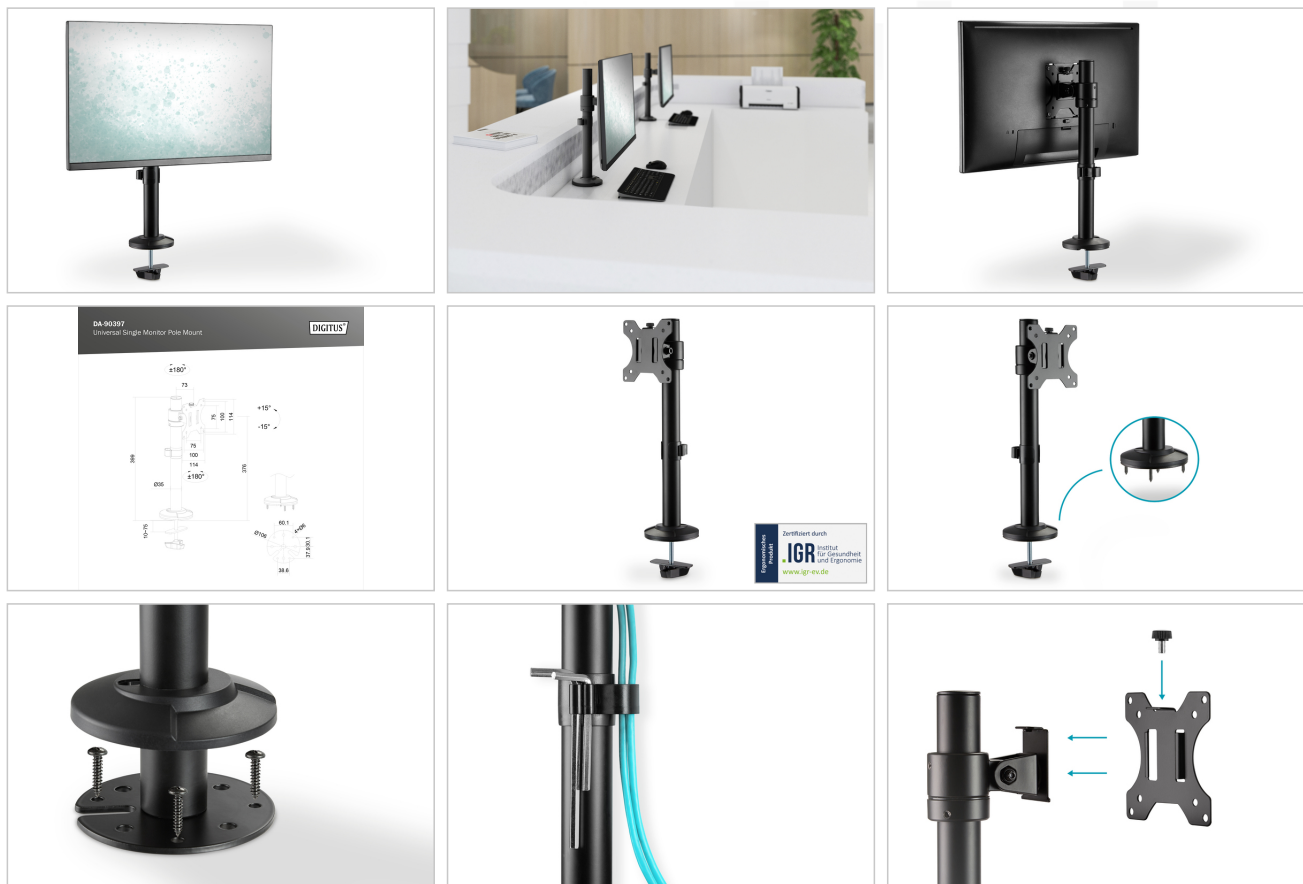

Safety notes

- Please read the entire manual before starting assembly and installation. Please contact your local dealer if you have any questions about the instructions or warnings.
- CAUTION: Use with products that exceed the permitted weight may result in damage or possible injury.
- Brackets should be fitted in accordance with the installation instructions. Incorrect installation can result in damage or injury.
- Use safety equipment and suitable tools. The product should only be installed by specialists.
- This product can be installed on timber-framed, solid concrete or stone walls.
- The load-bearing surfaces should be able to safely withstand the entire weight of appliances and all additional components.
- Only use the installation screws supplied and DO NOT TIGHTEN the screws TOO TIGHT.
- This product contains small parts that can cause a choking hazard if swallowed. Keep these parts away from children.
- Only use this product indoors. Using the product outdoors can lead to injury and damage.
- IMPORTANT: Before installation, please check all components received against the components list. If parts are damaged or missing, ask your local dealer for replacement parts.
- MAINTENANCE: Check the bracket regularly for safety and stability (preferably every three months).

EU responsible person

EU based economic operator ensuring the product complies with the required regulations.

ASSMANN Electronic GmbH
Auf dem Schüffel 3
Lüdenscheid, Germany
<https://www.assmann.com>
info@assmann.com