


# E37910



## Thermowell for temperature sensors

THERMOWELL, D6/2" CLAMP/L=100

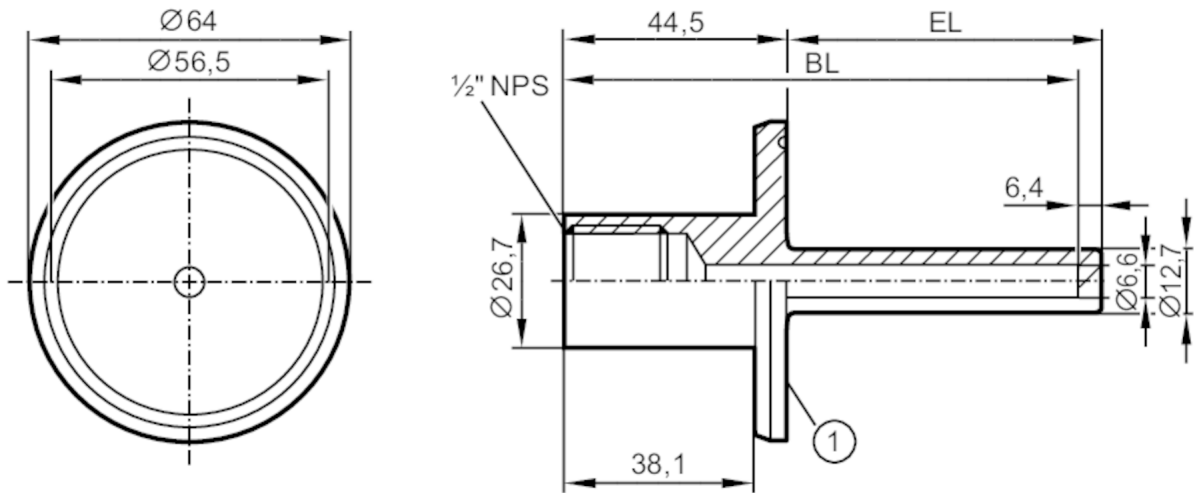

1 Clamp 2" ISO 2852



EC 1935/2004 EHEDG Certified



### Application

|                 |                                     |     |
|-----------------|-------------------------------------|-----|
| Design          | for temperature sensors EL = 100 mm |     |
| Pressure rating | [bar]                               | 25  |
| Pressure rating | [MPa]                               | 2.5 |

### Mechanical data

|                                                   |                                                |       |
|---------------------------------------------------|------------------------------------------------|-------|
| Weight                                            | [g]                                            | 296.2 |
| Materials                                         | stainless steel (316L/1.4404)                  |       |
| Sensor connection                                 | 1/2" NPS Ø 6 mm suitable for G1/2 and 1/2" NPT |       |
| Process connection                                | Clamp DN50 (2") DIN 32676 (ISO 2852)           |       |
| Surface characteristics Ra/Rz of the wetted parts | ≤ 0.6 / -                                      |       |
| Installation length EL                            | [mm]                                           | 64    |
| Bore length BL                                    | [mm]                                           | 101.6 |

### Remarks

|               |        |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|