






Kompletny, uniwersalny system obudów modułowych, doskonale integrowalny z produktami z serii do użytku domowego SYSTEM i umożliwiający spełnianie wysokich wymogów bezpieczeństwa instalacji montowanych w środowiskach mieszkalnych, handlowych i uprzemysłowionych. Seria produktów COMBI 27 dostępna jest zarówno w wykonaniu IP40, jak i w wykonaniu wodoszczelnym o stopniu ochrony IP55, IP65 oraz IP66, zalecanym do wszystkich zastosowań zewnętrznych narażonych na działanie skrajnych warunków atmosferycznych.

Opis	2 miejsca	Kolor	Szary RAL 7035
Liczba otworów do wybicia Ø23	3 po bokach / 1 na dole	Liczba otworów Ø 23 z dławikiem kablowym	1
Typy wybitych otworów	Wymienne przy użyciu narzędzia	Ochrona IP	IP40
Klasa Izolacji	II	Odporność na wstrząsy	IK07
Charakterystyka	Bezhalogenowy	Śruby pokrywy	Stal odporna na korozję
Moment dokręcania moment dokręcania śrub	0.8 NM	Śred. zewn. LxHxD (mm)	66x82x55
Próba rozżarzonym drutem	650 °C	Twardość kulkowa	70 °C
Norma	(EN 60670-1)	Montaż Temperatury	-25 +60 °C
Electrocod	0212		

BEHAVIOUR WITH CHEMICAL AND ATMOSPHERIC AGENTS

Saline solution	Acids		Bases		Solvents				Mineral oil	UV rays
	Concentrated	Diluted	Concentrated	Diluted	Hexane	Benzol	Acetone	Alcohol		
Resistant	Limited resistance	Resistant	Resistant	Resistant	Limited resistance	Not resistant	Not resistant	Not resistant	Limited resistance	Resistant

DIMENSIONAL

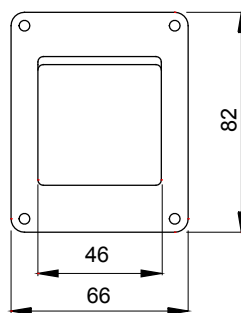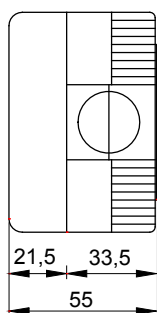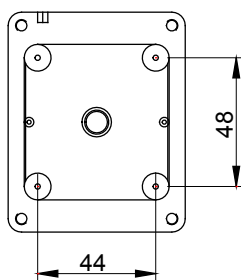

TECHNICAL SYMBOLOGY



Wymienne przy użyciu narzędzia

IP

IP40



II

IK

IK07



Bezhalogenowy

GWT

650 °C



70 °C

STANDARDS/APPROVALS

