




DIN 7981 C

~ISO 7049

Norme abrogée

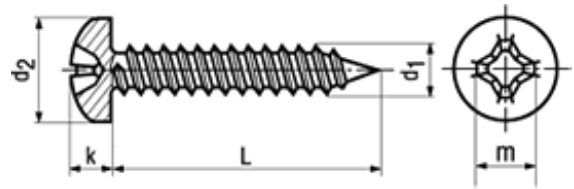

BN 695

Vis à tête cylindrique bombée

avec empreinte cruciforme Phillips forme H et à bout pointu forme C

INOX A2

- ~UNI 6954 AB
- ~ČSN 021235

[3D Cadenas](#)

Article#	d ₁	d ₂ max.	k max.		m~	L
1214225	ST2,2	4,2	1,8	1	2,6	6,5
1214233						9,5
1214241						13
1675613						16
1675621						19
1261819	ST2,9	5,6	2,2	1	3	6,5
1261827						9,5
1261835						13
1261843						16
1261851						19
1261878						22
1261886						25
1261894	ST3,5	6,9	2,6	2	4,2	6,5
1261908						9,5
1261916						13
1261924						16
1261932						19
1261940						22
1261959						25
1261967						32
1261975						38
3059888						45
1675648	(ST3,9)	7,5	2,8	2	4,4	6,5
1261983						9,5
1261991						13
1262009						16
1262017						19

Article#	d ₁	d ₂ max.	k max.		m~	L
1262025	(ST3,9)	7,5	2,8	2	4,4	22
1262033						25
1262041						32
1262068						38
3059889						45
1262076	ST4,2	8,2	3,05	2	4,6	9,5
1262084						13
1262092						16
1262106						19
1262114						22
1262122						25
1262130						32
1262149						38
1262157						45
1397419						50
3059890						60
3059891						70
1262165	ST4,8	9,5	3,55	2	5	9,5
1262173						13
1262181						16
1262203						19
1262211						22
1262238						25
1262246						32
1262254						38
1262262						45
1262270						50
2094274						60
2094282						70
2094290						80
1262289	ST5,5	10,8	3,95	3	6,5	13
1262297						16
1262300						19
1262319						22
1262327						25
1262335						32
1262343						38
1262351						45
1262378						50
5514322						55
2094304						60

Article#	d ₁	d ₂ max.	k max.		m~	L
2094312	ST5,5	10,8	3,95	3	6,5	70
2094320						80
1262386	ST6,3	12,5	4,55	3	7,1	13
1262394						16
1262408						19
1262416						22
1262424						25
1262432						32
1262440						38
1262459						45
1262467						50
2094339						60
2094347						70
2094355						80