





Visual Signals FLASHING FILAMENT BEACONS

Industrial LED Multi Functional > LEDD & LEDA 125 Series

Product overview

Suitable for fire, security & industrial applications, these beacons offer three alternative light mode operations: Continuously ON, Rapid Flash 120 FPM or Standard Flash 60FPM, selected by a dip switch mounted lens side on

the PCB. The LEDA version incorporated two Piezo sounders situated in their base that are synchronised to the light mode. 'Ac' units are supplied with one meter of flying lead. 'Dc' units allow for termination inside the base enclosure. An M12 sealing gromet in the base allows for cable entry.

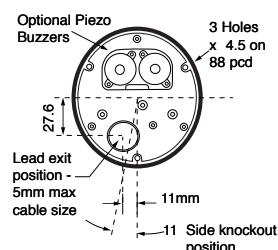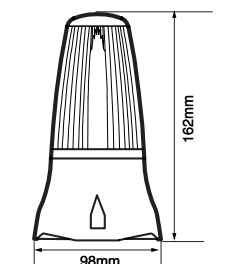

Features

- LED long life
- Extra bright
- Continuously rated
- Combined audible & visual signal
- Cage guard option - see accessory page
- 360° visibility
- 3 point fix

Material

- UV Stable Polycarbonate Lens
- UV Stable ABS Plastic Base



Code No:	Voltage:	Light Source:	Current:			
			01	02	03	04
LEDD125-02	24v Dc ---	48 LEDs	450 mA	250 mA	250 mA	250 mA
LEDD125-03	115v Ac ~	48 LEDs	450 mA	250 mA	250 mA	250 mA
LEDD125-04	230v Ac ~	48 LEDs	450 mA	250 mA	250 mA	250 mA
For Audible Option						
LEDA125-02	24v Dc ---	48 LEDs	450 mA	250 mA	250 mA	250 mA
LEDA125-03	115v Ac ~	48 LEDs	450 mA	250 mA	250 mA	250 mA
LEDA125-04	230v Ac ~	48 LEDs	450 mA	250 mA	250 mA	250 mA

Kg 0.57Ac 0.33Dc

50/60 Hz

°C -20+45

IP 65

FPM 60/120

INDUSTRIAL

APPROVAL AND CONFORMITIES



ADD THE FOLLOWING LENS CODES TO THE PRODUCT CODE WHEN ORDERING

01 02 03 04

dB 90

FIRE