




DIN 125 A

~ISO 7089

Norma ritirata

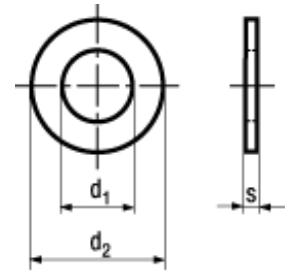

BN 560

Rosette piane

senza smusso

Ottone

grezzo

- VSM 13904
- ~UNI 6592
- ~ČSN 021702

Article#		d ₁	d ₂	s
1215639	M2	2,2	5	0,3
1759167	M2,5	2,7	6	0,5
1215698	M3	3,2	7	0,5
1215728	M4	4,3	9	0,8
1215744	M5	5,3	10	1
1759175	M6	6,4	12	1,6
1759442	M8	8,4	16	1,6
1759507	M10	10,5	20	2