




DIN 963 A

~ISO 2009

4.8

Norma ritirata

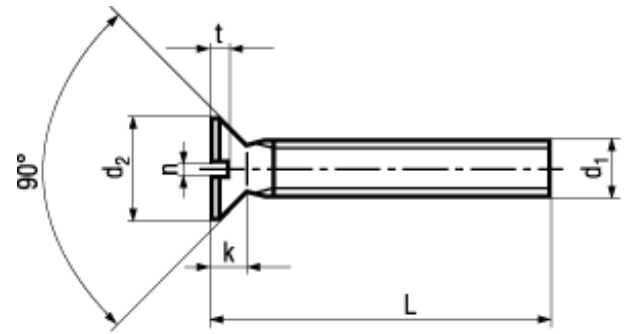

BN 359

Viti a testa svasata piana

con intaglio

Acciaio 4.8

zincato giallo

- ~UNI 6109
- ~ČSN 021151

 [3D Cadenas](#)

 Tutte le misure con filettatura quasi completa
Realizzare la sede per testa svasata secondo la norma di riferimento!

Article#	d ₁	d ₂ max.	k max.	n	t min.	L
1141732	M2,5	4,7	1,5	0,6	0,5	4
1141740						5
1141759						6
1141767						8
1141775						10
1141805						16
1141945	M3	5,6	1,65	0,8	0,6	4
1141953						5
1141961						6
1141988						8
1141996						10
1142003						12
1142038						16
1142046						(18)
1142054						20
3056171						25
5523890						30
1142100						35
1142119						40
1142127	M4	7,5	2,2	1	0,8	5
1142135						6
1142143						8
1142151						10
1142178						12
1142194						16
1142216						20

Article#	d ₁	d ₂ max.	k max.	n	t min.	L
1142232	M4	7,5	2,2	1	0,8	25
1142259						30
1142275						40
1142291	M5	9,2	2,5	1,2	1	8
1142305						10
1142313						12
1142348						16
1142364						20
1142380						25
1142402						30
1142410						35
1142429						40
8046255						60
8130817	M6	11	3	1,6	1,2	8
1142437						10
1142445						12
1142461						16
1142496						20
1142526						25
1142542						30
1142550						35
1142569						40
1142585						50