




DIN 84 A

~ISO 1207

4.8

Norma ritirata

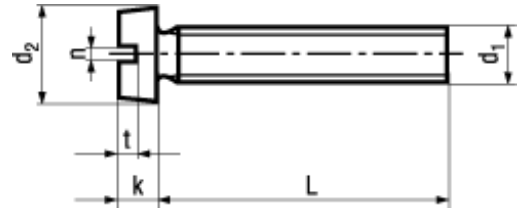

BN 328

Viti a testa cilindrica

con intaglio

Acciaio 4.8

grezzo

- ~UNI 6107
- ~ČSN 021131

[3D Cadenas](#)

Tutte le misure con filettatura quasi completa

Article#	d ₁	d ₂	k max.	n	t min.	L
1120336	M2	3,8	1,3	0,5	0,6	3
1120344						4
1120352						5
1120360						6
1120379						8
1120387						10
1120395						12
1120417						16
1120433						20
1130277						25
1130285						30
1120786	M2,5	4,5	1,6	0,6	0,7	3
1120794						4
1120808						5
1120816						6
1120824						8
1120832						10
1120840						12
1120867						16
1120883						20
1130293						25
1121065	M3	5,5	2	0,8	0,85	3
1121073						4
1121081						5

Article#	d ₁	d ₂	k max.	n	t min.	L
1121103	M3	5,5	2	0,8	0,85	6
1121138						8
1121146						10
1121154						12
1121170						16
1121197						20
1121219						25
1121235						30
1130307						35
1121510	M4	7	2,6	1,2	1,1	4
1121529						5
1121537						6
1121545						8
1121553						10
1121561						12
1121596						16
1121626						20
1121642						25
1121669						30
1130455						40
1130463						45
1121790	M5	8,5	3,3	1,2	1,3	6
1121804						8
1121812						10
1121820						12
1121847						16
1121863						20
1121898						25
1121928						30
1130528						35
1121944						40
3056128	M6	10	3,9	1,6	1,6	8
1122045						10
1122053						12
1122088						16
1122118						20
1122134						25
1122150						30
1130595						40