

USB Type-C™ Dual HDMI Adapter with 4K 60 Hz and USB Port

Description

This adapter by Delock can be connected to a computer, laptop or mobile device with a USB-C™ DP Alt Mode or Thunderbolt™ 3 port. **Two monitors, projector or TVs** can be operated at the HDMI outputs **simultaneously**.

4K 60 Hz UHD resolution

If one HDMI port of the adapter is used, a maximum resolution of 4K 60 Hz is available. If both ports are used at the same time, the maximum resolution per monitor is 4K 30 Hz.

Additional USB Type-A port

A USB memory, mouse or keyboard can be connected to the **USB Type-A port** to turn the smartphone into a home office workstation.

Multi-Stream Transport (MST)

The product is an MST hub and supports the extended desktop configuration of DisplayPort. This allows multiple monitors to be combined into one large display. The maximum resolution for simultaneous playback on two or three monitors depends on the system and connected hardware.

Small sturdy helper

Due to its **small dimensions and its sturdy housing**, this Delock adapter is particularly suitable for travelling. It can simply be packed into the bag together with the laptop and used as needed.

Please Note

Only one additional external monitor can be connected to MacBook devices with M1, M2 and M3 chipset. MacBook devices with M1 Pro, M2 Pro, M3 Pro and M3 Max chipset can connect two or more additional external monitors. Further information is available at www.apple.com.



Item no. 87780

EAN: 4043619877805

Country of origin: China

Package: Retail Box

Technical details

- Connectors:
 - 1 x USB Type-C™ male
 - 2 x HDMI female
 - 1 x USB 2.0 Type-A female
- Maximum resolution:
 - 1 display: up to 3840 x 2160 @ 60 Hz
 - 2 displays: up to 3840 x 2160 @ 30 Hz
 - (depending on the system and the connected hardware)
- Transmission of audio and video signals
- Functions: Mirrored or Extended, with Mac OS and Chrome only
one monitor can be extended, all others are mirrored
- Supports HDCP
- Data transfer rate up to 480 Mb/s (USB Type-A)
- 1 x LED indicator
- Metal housing
- Colour: grey
- Cable length: ca. 15 cm
- Dimensions (LxWxH): ca. 90 x 30 x 11 mm


System requirements

- Android 10.0 or above
- Chrome OS 87.0 or above
- iPad Air (4th Generation) or above
- iPad Pro (3rd Generation) or above
- Linux Kernel 5.4 or above
- Mac OS 11.0.1 or above
- Surface Pro 7
- Windows 8.1/8.1-64/10/10-64
- Device with a free USB Type-C™ port and DisplayPort alternate mode or with a free Thunderbolt™ 3 port

Package content

- Adapter
- User manual

Images

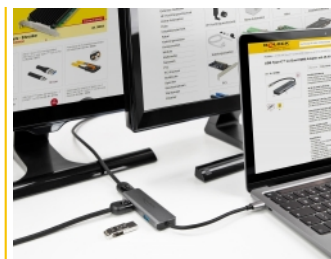

General

Supported operating system:	Linux Kernel 5.4 or above Mac OS 11.0.1 or above Surface Pro 7 Windows 10 32-Bit Windows 10 64-Bit Windows 8.1 32-Bit Windows 8.1 64-Bit Android 10.0 or above iPad Pro (3rd Generation) or above Chrome OS 87.0 or above iPad Air (4th Generation) or above
LED indicator:	1 x

Interface

Connector 1:	1 x USB Type-C™ male
Connector 2:	2 x HDMI-A female
Connector 3:	1 x USB 2.0 Type-A female

Technical characteristics

Maximum screen resolution:	3840 x 2160 @ 60 Hz
----------------------------	---------------------

Physical characteristics

Housing material:	Aluminium
Cable length:	15 cm
Length:	90 mm
Width:	30 mm
Height:	11 mm
Colour:	grey

Manufacturer information

Street Beeskowdamm 13/15
Postal code 14167

City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de