

USB Dual Docking Station for 2 x SATA HDD / SSD with Clone and Erase Function

Description

This docking station by Delock enables an external connection of up to **two 2.5" or 3.5" SATA HDDs or SSDs** through the USB interface. This solution does not require an external enclosure since the drive can be plugged into the docking station directly.

Clone and erase function

The clone function enables to copy the content of one HDD to another without using a PC. No connection to the computer is required for the **erase function**. Selectively one drive or two drives can be deleted at the same time.



Item no. 64187

EAN: 4043619641871

Country of origin: China

Package: Retail Box

Technical details

- Connectors:
 - 1 x USB 5 Gbps Type-B female
 - 2 x SATA 6 Gb/s 22 pin receptacle
 - 1 x DC jack
- Chipset: Asmedia ASM1156
- Function key:
 - 1 x Clone button
 - 1 x Erase button
 - 1 x On / Off switch
- Erase procedure: overwrite the entire memory with "0"
- For 2.5" and 3.5" SATA HDD / SSD
- Suitable for all SATA HDDs up to SATA 6 Gb/s
- Data transfer rate up to 5 Gbps
- LED indicator for power, access and copy / erase status
- Dimensions (LxWxH): ca. 153 x 110 x 62 mm
- Plug & Play

Power supply specification

- Wall power supply
- Input: AC 100 ~ 240 V / 50 ~ 60 Hz / 1.5 A

- Output: 12.0 V / 3.0 A
- Ground outside, plus inside
- Dimensions:
 - inside: ø ca. 2.1 mm
 - outside: ø ca. 5.5 mm
 - length: ca. 10 mm


System requirements

- Chrome OS
- Linux Kernel 5.13 or above
- Mac OS 12.4 or above
- Windows 8.1/8.1-64/10/10-64/11
- PC or laptop with a free USB Type-A port

Package content

- Docking station
- Cable USB Type-A male to Type-B male, length ca. 80 cm
- External power supply 12.0 V / 3.0 A
- User manual

Images

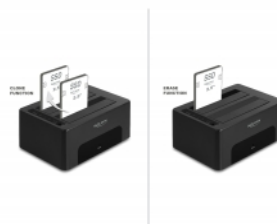

General

Function:	Clone Function Erase function
Suitable for data medium:	2.5" 3.5" SSD or HDD
Supported operating system:	Chrome OS Windows 10 32-Bit Windows 10 64-Bit Windows 8.1 32-Bit Windows 8.1 64-Bit Windows 11 Mac OS 12.4 oder höher Linux Kernel 5.13 or above

Interface

External:	1 x DC jack 1 x USB 5 Gbps Type-B female
Internal:	2 x SATA 22 Pin Buchse

Technical characteristics

Chipset:	Asmedia ASM1156
Data transfer rate:	5 Gbps

Physical characteristics

Housing material:	Plastic
Length:	153 mm
Width:	110 mm
Height:	62 mm
Colour:	black

Manufacturer information

Street Beeskowdamm 13/15

Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de