




- Ball head makes it possible to work at an angle of up to 30° to screw axis.
- For tightening, use short side, if possible.

	Art.	mm	L mm	L1 mm	g
000960960	96BP 1,5	1,5	79	13	1,4
000960961	96BP 2	2	84	15	2,7
000960962	96BP 2,5	2,5	89	17	4,5
000960963	96BP 3	3	99	19	6
000960965	96BP 4	4	108	24	13
000960967	96BP 5	5	126	27	25,7
000960968	96BP 6	6	148	31	39
000960970	96BP 8	8	168	35	88,2
000960972	96BP 10	10	187	39	145
000960973	96BP 12	12	220	55	165

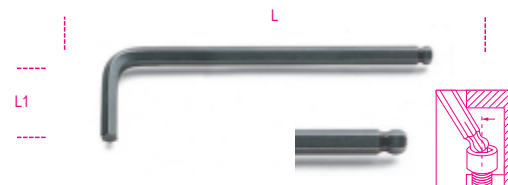

Scan the QR Code to access the web tab
Specs, media and documentation in one click.

