


WM-75T-04

TV wall mount (tilt), 37"-75"

- Position your screen perfectly
- Lightweight and tilting design

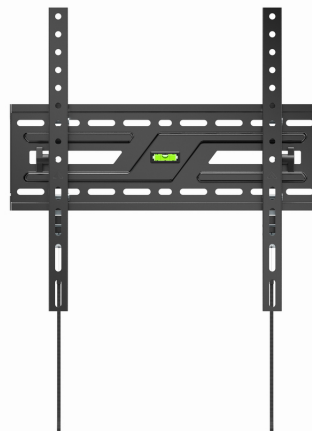

Features

- Heavy duty steel LCD screen wall mount
- Supports most 37" 75" LCD TV's
- VESA compatible, max. 400 mm x 400 mm
- Allows up 15 degrees tilting
- Easy-grip knobs for quick tilting adjustment
- Automatic spring locks with quick release cords allow quick and easy TV fixation and removal
- Practical integrated bubble level for perfect alignment
- Distance to wall: 50 mm
- Includes all necessary installation materials

Packaging

Q'ty in crtn, pcs
Crtn volume, CUM
Crtn weight, kgs
Individual package size LxWxH:
Carton size LxWxH:
Country of origin
Barcode
Customs code

10
0.043630776
19.89
445x156x53 mm
447x332x294 mm
CN
8716309135306
8302500000

Package contents

Wall mount elements
Installation accessories kit
Installation manual

Specifications

Material: steel
Surface finish: powder coating
Color: fine texture black
Supported screen size: 37" 75"
VESA compatible: 75x75, 100x100, 100x150, 150x100, 100x200, 200x100, 150x150, 200x200, 200x300, 300x200, 200x400, 400x200, 300x300, 300x400, 400x300, 400x400
Weight capacity: 75 kg
Profile: 50 mm
Tilt range: 5° ~ -10°
Swivel range: n/a
Screen level: n/a
Installation: solid wall, double stud (406 mm)

Certificates

