


PoweredUSB cable male 12 V > PoweredUSB male 12 V 4 m for POS printers and terminals

Description

This PoweredUSB cable by Delock can be used to connect a device with PoweredUSB 12 V port to a PC or hub with PoweredUSB 12 V port. It is suitable for connecting various POS devices such as printers and terminals, e.g. by Epson, Honeywell or IBM. The cable is used both for data transmission and for power supply of the connected device.

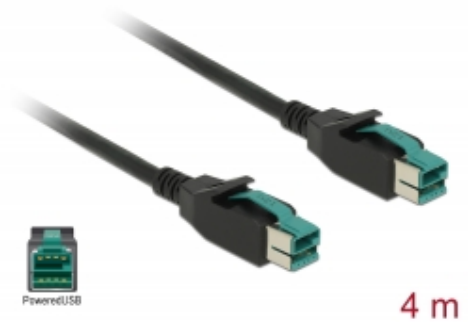

Item no. 85495

EAN: 4043619854950

Country of origin: China

Package: Zip poly bag

Technical details

- Connectors:
1 x PoweredUSB male 12 V >
1 x PoweredUSB male 12 V
- PoweredUSB specification
- Voltage: 12 V
- Cable gauge:
26 AWG data line
20 AWG power line
- Cable diameter: ca. 6.5 mm
- Cable double shielded
- Data transfer rate up to 480 Mbps
- Colour: black
- Length incl. connectors (L): ca. 4 m


System requirements

- PC or hub with a free PoweredUSB 12 V female port
- Device with a free PoweredUSB 12 V female port

Package content

- PoweredUSB cable

Images

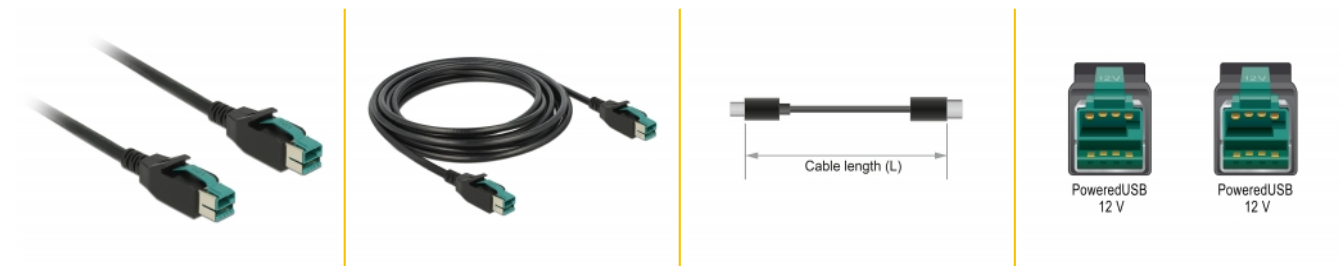

General

Specification:	PoweredUSB
Style:	both sides identical

Interface

Connector 1:	1 x PoweredUSB male 12 V
Connector 2:	1 x PoweredUSB male 12 V

Technical characteristics

Data transfer rate:	USB 2.0 up to 480 Mb/s
Voltage:	12 V

Physical characteristics

Cable gauge:	26 AWG data line 20 AWG power line
Shielding:	double
Length:	4 m
Colour:	black

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de

