




81921501-Simple plunger




Symbol NO

Symbol NC	
Operating pressure (bar)	0,1→8
Orifice diameter mm	2,7
Flow at 6 bars NI/min	200
Actuation force at 6 bars N	18
Circuit function: NF	✓
Circuit function: NO	-
Operating temperature (° C)	-5 +50
Mechanical life (operations)	≥ 10 ⁷
Weight (g)	62

Dimension Diagram : 81 921 501

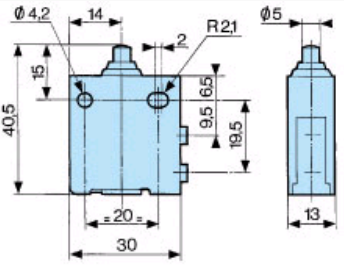


: NC

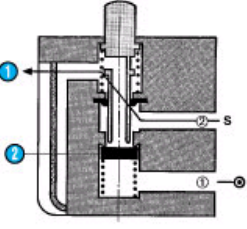

N°	Legend
1	Exhaust
2	Poppet

: Actuation travelVerticla attack - Simple plunger

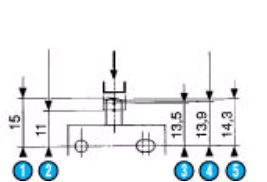

N°	Legend
1	PR: Rest position
2	PFC: End of travel position

- 3 PA: Operating position (max output kV)
- 4 PO: Mid-position closed (no exhaust, no outlet)
- 5 PRT: Release position (max exhaust kV)