

MANUAL BARREL LOADERS

The 560548U Series of manual barrel loaders will fill a barrel directly from a 6 oz, 12 oz, 300 ml, 20 oz, or 32 oz.

Barrel loaders are connected to an air regulator and set to a pressure suitable for the material not exceeding 65 psi (4.48 bar). A manual switch on the base actuates the air supply and pressurizes the cartridge to fill the syringe barrel.

The barrel fillers' internal air relief valve allows for decompression when the trigger is released. The system can be used for timed filling when connected to a Fisnar automatic controller.


Item Number	Description
560548U-6N	6 oz Nylon Barrel Loader
560548U-12N	12 oz Nylon Barrel Loader
560548U-300	300 ml Metal Barrel Loader
560548U-570	20 oz Metal Barrel Loader
560548U-910	32 oz Metal Barrel Loader

Replacement Parts

Item Number	Description
561105	1/4" NPT Elbow
5801451	Syringe Filling Adapter
560710	Luer Lock Cap
560546	1/4" NPT Polyethylene Female Cartridge Adapter
561129	1/4" NPT x 5/8-11 UNC White Acetal Cartridge Adapter
562317	1/4" NPT x 13/16-14 UNC Black Acetal Cartridge Adapter

Replacement Seals

Item Number	Description
5801388-SEAL	Seal (NBR) for Retainer Cap
CR300-SEAL	Seal (NBR) for Retainer Cap
CR570-SEAL	Seal (NBR) for Retainer Cap
CR910-SEAL	Seal (NBR) for Retainer Cap

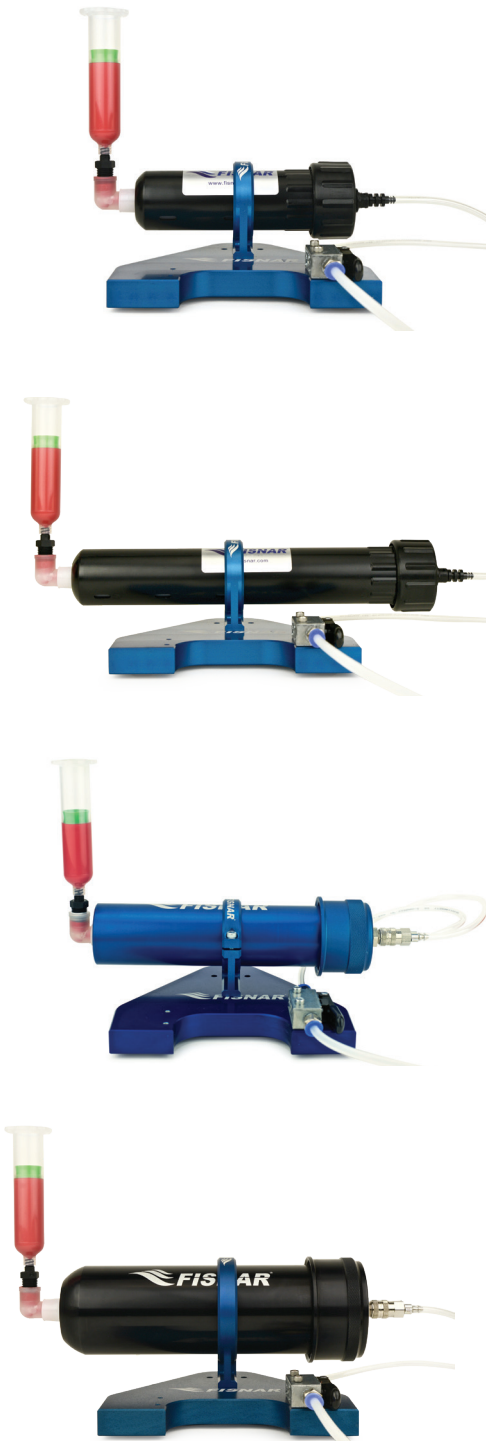

50 ML MANUAL BARREL LOADER

The 560548U-DTD50 manual barrel loader will fill a syringe barrel directly from A-style or B-style square back 50 ml cartridges with a 1:1, 2:1, 3:2, 4:1, or 10:1 ratio.

Barrel loaders are connected to an air regulator and set to a pressure suitable for the material not exceeding 65 psi (4.48 bar). A manual switch on the base actuates the air supply and pressurizes the cartridge to fill the syringe barrel.

The barrel fillers' internal air relief valve allows for decompression when the trigger is released. The system can be used for timed filling when connected to a Fisnar automatic controller.

Item Number	Description
560548U-DTD50	50 ml Dual Cartridge Barrel Loader

Spare Parts

Item Number	Description	
EAMAH05-17LL	5.4 mm x 17 Element LL Mix Nozzle (A-Style)	
FMAH250-20LL	0.250" x 20 Element LL Mix Nozzle (A-Style)	
EAMBH05-16LL	5.4 mm x 16 Element LL Mix Nozzle (B-Style 1:1/2:1)	
EAMBHX05-16LL	5.4 mm x 16 Element LL Mix Nozzle (B-Style 4:1/10:1)	
562358	Female Luer Elbow	
560710	Luer Lock Cap	