


UNI-ISO 10102 DIN 3110

- Compact heads.
- Torque values significantly higher than ISO 1711-1 standards

		Art.	M mm	M1 mm	L mm	H mm	H1 mm	S mm	g	
		000550003	55 4X5	5	4	101	14	12,5	3	12
		000550006	55 5X5,5	5,5	5	101	14	12,5	3	12
		000550009	55 5,5X7	7	5,5	120	17,5	15,5	3,5	21
•		000550012	55 6X7	7	6	120	17,5	15,5	3,5	21
		000550018	55 7X8	8	7	140	21,5	19,5	4	32
•		000550021	55 8X9	9	8	140	21,5	19,5	4	34
		000550024	55 8X10	10	8	140	21,5	19,5	4	34
•		000550030	55 10X11	11	10	155	25,5	23,5	4,5	47
		000550033	55 10X12	12	10	155	25,5	23,5	4,5	45
		000550035	55 10X13	13	10	170	29,5	27,5	5	68
•		000550042	55 12X13	13	12	170	29,5	27,5	5	69
		000550051	55 13X17	17	13	189	37,5	31,5	6	114
•		000550054	55 14X15	15	14	185	33,5	31,5	5,5	92
•		000550060	55 16X17	17	16	202	37,5	35,5	6	122
		000550063	55 17X19	19	17	220	41,5	39,5	6,5	147
•		000550066	55 18X19	19	18	220	41,5	39,5	6,5	134
		000550069	55 19X22	22	19	236	47,5	43,5	7	204
•		000550075	55 20X22	22	20	236	47,5	43,5	7	207
•		000550078	55 21X23	23	21	245	49,5	45,5	7,6	245
		000550081	55 22X24	24	22	245	49,5	45,5	7,6	233
•		000550087	55 24X26	26	24	262	55,5	51,5	8	300
		000550090	55 24X27	27	24	262	55,5	51,5	8	310
•		000550096	55 25X28	28	25	272	59,5	53,5	8,6	359
•		000550099	55 27X29	29	27	284	61,5	57,5	8,8	393
•		000550108	55 30X32	32	30	297	67,5	63,5	9	490
		000550114	55 32X36	36	32	325	76,1	68,4	11	612
		000550117	55 34X36	36	34	325	76,1	68,4	11	614
		000550120	55 35X38	38	35	375	85,6	76	13	856
		000550123	55 36X41	41	36	375	85,6	76	13	858
		000550129	55 41X46	46	41	425	94,8	85,6	14	1200
		000550132	55 46X50	50	46	475	104	94,8	15	1785
		000550135	55 50X55	55	50	500	113,8	106,8	16	2000
		000550138	55 55X60	60	55	500	113,8	106,8	16	2350

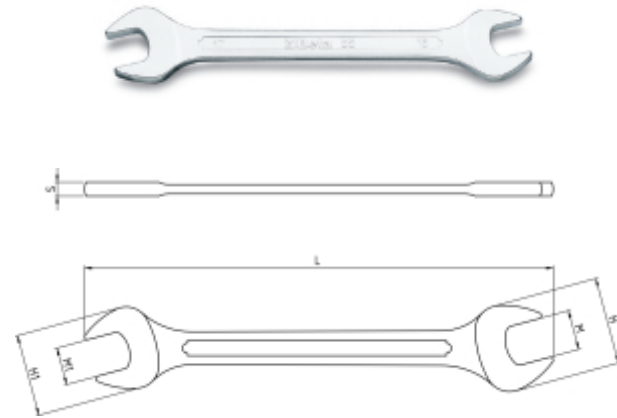

Scan the QR Code to access the web tab
Specs, media and documentation in one click.

