

Adapter USB Type-C™ to 1 x Serial RS-232 D-Sub 9 pin male with nuts 25 cm

Description

This USB Type-C™ to serial adapter by Delock provides a compatible RS-232 DB9 interface for printers, measuring instruments, controllers, IoT devices etc.



25 cm

Item no. 64307

EAN: 4043619643073

Country of origin: China

Package: Retail Box

Technical details

- Connectors:
 - 1 x USB Type-C™ male
 - 1 x serial RS-232 D-Sub 9 male with nuts
- Chipset: Prolific PL2303 GT
- Data transfer rate up to 921.6 Kbps
- Signals: TxD, RxD, RTS, CTS, DTR, DSR, DCD, RI, GND
- FIFO: 1024 byte
- Plug & Play
- Colour: black
- Cable length with connectors: ca. 25 cm

 

System requirements

- Android 13.0 or above
- Linux Kernel 6.5 or above
- Windows 10/10-64/11
- PC or laptop with a free USB Type-C™ or Thunderbolt™ 3/4/5 port

Package content

- USB Type-C™ to 1 x serial adapter
- User manual

Images

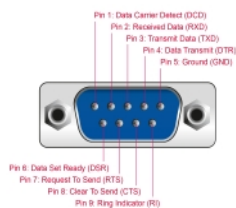

General

Function:	Plug & Play
Specification:	RS-232 (EIA / TIA) Thunderbolt™ 3 Thunderbolt™ 4 UHCI/OHCI/EHCI USB 2.0 USB Type-C™
Supported operating system:	Linux Kernel 2.6 or above Windows 10 32-Bit Windows 10 64-Bit Windows 7 32-Bit Windows 7 64-Bit Windows 8.1 32-Bit Windows 8.1 64-Bit Windows 11 Android 13.0 or above

Interface

Output:	1 x Serial RS-232 DB9 male
Input:	1 x USB Type-C™ male

Technical characteristics

Chipset:	Prolific PL2303GT
Data transfer rate:	921.6 Kbps
FIFO:	1 x 256 byte transmit 1 x 768 Byte empfangen
Signal transmission:	TxD, RxD, RTS, CTS, DTR, DSR, DCD, RI, GND
Data transmission:	asynchronous full duplex
UART:	USB to serial UART
Data bits:	5, 6, 7, 8
Stop bits:	1, 1.5, 2

Physical characteristics

Cable length incl. connectors:	25 cm
Pin finishing:	gold-plated
Cable gauge:	28 AWG data line 24 AWG power line
Screw type:	#4-40 UNC
Shielding:	double
Colour:	black

Manufacturer information

Street	Beeskowdamm 13/15
Postal code	14167
City	Berlin
Country	Deutschland
E-Mail	info@delock.de
Website	www.delock.de